

Branch Line Restraint Pipe Attachment



CERTIFICATIONS



VLASTNOSTI

Accepts 3/8" or 1/2" (M10 or M12) threaded rod

Quick grip clamp simplifies measuring and cutting of threaded rod

Eliminates need to cut threaded rod to exact dimensions

Works with rough-cut threaded rod and eliminates pipe-side deburring

Can be installed with threaded rod above or below the service pipe

Shear-off head helps ensure correct torque and simplifies inspection

SPECIFIKACE

Povrchová úprava: Electrogalvanized

Materiál: Ocel

Table 1/2


Katalogové číslo	Article Number	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Height (H)	Length (L)
CSBBRP0200E G	404480	50	60.3 mm	10, 12	100.3 mm	68.3mm

Katalogové číslo	Article Number	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Height (H)	Length (L)
CSBBRP0125E G	404478	32	42.2 mm	10, 12	82.6 mm	50mm
CSBBRP0150E G	404479	40	48.3 mm	10, 12	88.9 mm	56.1mm
CSBBRP0100E G	404477	25	33.4 mm	10, 12	73.7 mm	41.4mm

Table 2/2

Katalogové číslo	Article Number	Width (W)
CSBBRP0200EG	404480	22.2 mm
CSBBRP0125EG	404478	22.2 mm
CSBBRP0150EG	404479	22.2 mm
CSBBRP0100EG	404477	22.2 mm

DIAGRAMS

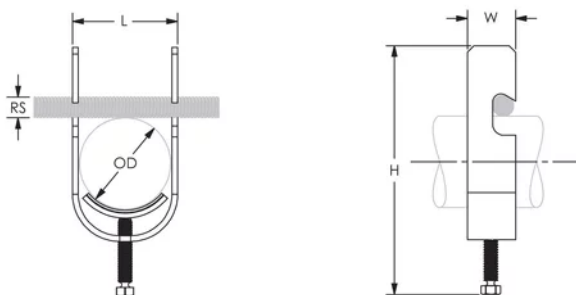

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

