

Drop-In Anchor



CERTIFICATIONS



VLASTNOSTI

Internal thread provides easy removal and serviceability

Installs flush or below the base surface

Suitable for redundant non-structural systems on cracked and non-cracked concrete

Fire resistance class R30-R120 for design of anchorages under exposure to fire

SPECIFIKACE

Table 1/2

Katalogové číslo	Article Number	Materiál	Povrchová úprava	Hole Size (HS)	Length (L)	Drill Bit Diameter
CAM6030	593180	Ocel	Electrogalvaniz ed	6 mm	30mm	8mm
CAM8030S6	401154	Stainless Steel 316 (EN 1.4401)		8 mm	30mm	10mm
CAM8030	593190	Ocel	Electrogalvaniz ed	8 mm	30mm	10mm

Katalogové číslo	Article Number	Materiál	Povrchová úprava	Hole Size (HS)	Length (L)	Drill Bit Diameter
CAM10040	593200	Ocel	Electro galvanizovaná	10 mm	40mm	12mm
CAM10040S6	401155	Stainless Steel 316 (EN 1.4401)		10 mm	40mm	12mm
CAM12050	400415	Ocel	Electro galvanizovaná	12 mm	50mm	15mm

Table 2/2

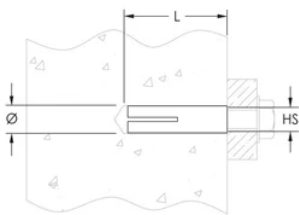
Katalogové číslo	Article Number	Certifications
CAM6030	593180	CE, 14-0135, CE, 14-0068
CAM8030S6	401154	CE, 14-0068, VdS
CAM8030	593190	CE, 14-0068, VdS, CE, 14-0135
CAM10040	593200	CE, 14-0068, FM Approved, Anchor, VdS, CE, 14-0135
CAM10040S6	401155	CE, 14-0068, VdS
CAM12050	400415	CE, 14-0068, FM Approved, Anchor, VdS, CE, 14-0135

Characteristic Axial Loads from ETA 14-0135

Part Number	Cracked Concrete C20/25	Non-Cracked Concrete C20/25	Standard Embedment Depth
CAM6030	-	2.50 kN	25 mm
CAM8030	-	3.30 kN	30 mm
CAM10040	-	4.40 kN	40 mm
CAM12050	-	6.10 kN	50 mm
CAM8030S6	-	-	-
CAM10040S6	-	-	-

Characteristic Axial Loads from ETA 14-0068 - for redundant non-structural systems

Part Number	Cracked Concrete C20/25	Non-Cracked Concrete C20/25	Standard Embedment Depth
CAM6030	0.80 kN	0.80 kN	25 mm
CAM8030	1.20 kN	1.20 kN	30 mm
CAM10040	1.70 kN	1.70 kN	40 mm
CAM12050	2.60 kN	2.60 kN	50 mm
CAM8030S6	1.20 kN	1.20 kN	25 mm
CAM10040S6	1.70 kN	1.70 kN	40 mm

DIAGRAMS**UPOZORNĚNÍ**

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY**ERICO****HOFFMAN****ILSCO****SCHROFF****TRachte**