


nVent CADDY Speed Link SLS Locking Device, 3 mm Wire

KATALOGOVÉ ČÍSLO

SLS3C50



CERTIFICATIONS

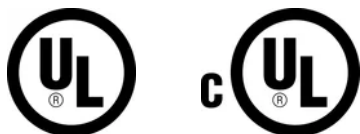

VLASTNOSTI

Single barrel locking device allows for quick prefabrication of strut or brackets

Push-on nut quickly and securely installs to strut or bracket to keep the locking device in position and eases installation

Finger tightening of nut secures the locking device into position without tools

Installs in strut profiles without the need to insert fingers or tools into the strut

Push-on nut guides the cable into the locking device and brings stability to the support

Installs with open side of the strut channel facing up or down for more flexibility

VLASTNOSTI PRODUKTU

Article Number: 196740

Materiál: Ocel; Polypropylene; Zinc Alloy

Wire Rope Diameter: 3 mm

Thread Size (TS): M12

Height 1 (H1): 53mm

Height 2 (H2): 46.5mm

Width (W): 20 mm

Thickness (T): 6 mm Max

Hole Size (HS): 12 - 14 mm

Slot Size (SS): 12 x 10 mm - 12 x 14 mm


DALŠÍ PODROBNOSTI O PRODUKTU

The 2 mm locking device is compatible with C-Channel Types E0 and E0L.

The 3 mm locking device is compatible with C-Channel Types E1, E2, E2L, E3, E4, E5, Strut Channel Type C, Slotted, Strut Channel Type A, Slotted, Strut Channel Type AS, Perforated, Strut Channel Type CC, Slotted, Strut Channel Type AA, Slotted.

Locking devices are only to be used with nVent CADDY Speed Link wire spools and accessories with the same specified Wire Rope Diameter as the locking device. Do not use with any other wires.

DIAGRAMS

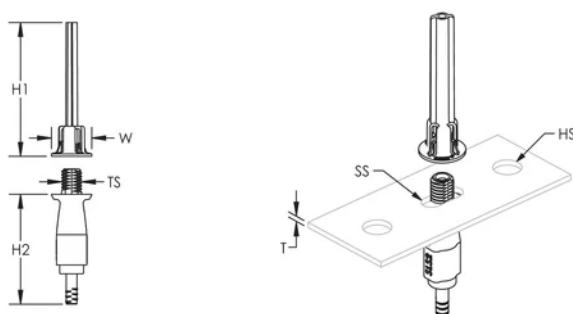

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

