

Flanged Drop-in Anchor



CERTIFICATIONS



VLASTNOSTI

Internal thread provides easy removal and serviceability

Installs flush for standard embedment

Suitable for redundant non-structural systems on cracked and non-cracked concrete

Fire resistance class R30-R120 for design of anchorages under exposure to fire

Lip makes the flush installation easier by helping achieve consistent anchor depth and easy threaded rod alignment

SPECIFIKACE

Povrchová úprava: Electrogalvanized

Materiál: Ocel

Table 1/1


Katalogové číslo	Article Number	Hole Size (HS)	Length (L)	Drill Bit Diameter (Ø)	Certifications
LAM625	589890	6 mm	25mm	8 mm	CE, 14-0068, CE, 14-0135
LAM830	574410	8 mm	30mm	10 mm	CE, 14-0135, CE, 14-0068, VdS

Katalogové číslo	Article Number	Hole Size (HS)	Length (L)	Drill Bit Diameter (Ø)	Certifications
LAM1040	574420	10 mm	40mm	12 mm	CE, 14-0068, VdS, CE, 14-0135
LAM1250	574430	12 mm	50mm	15 mm	CE, 14-0135, CE, 14-0068, VdS

Characteristic Axial Loads from ETA 14-0135			
Part Number	Cracked Concrete C20/25	Non-Cracked Concrete C20/25	Standard Embedment Depth
LAM625	-	2.44 kN	25 mm
LAM830	-	3.21 kN	30 mm
LAM1040	-	4.23 kN	40 mm
LAM1250	-	5.92 kN	50 mm

Characteristic Axial Loads from ETA 14-0068 - for redundant non-structural systems			
Part Number	Cracked Concrete C20/25	Non-Cracked Concrete C20/25	Standard Embedment Depth
LAM625	0.80 kN	0.80 kN	25 mm
LAM830	1.20 kN	1.20 kN	30 mm
LAM1040	1.70 kN	1.70 kN	40 mm
LAM1250	2.60 kN	2.60 kN	50 mm

DIAGRAMS

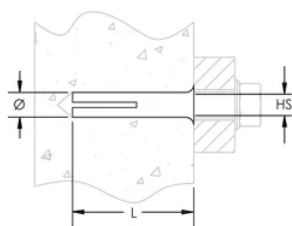

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

