

# Hammer-On Flange Clip, Vertical Mount with Stud



## VLASTNOSTI

Can be used to support boxes, fixtures or other applications from beam flanges

Captive threaded stud minimizes the need for additional hardware

Fits most beams

Requires only a hammer to install


## SPECIFIKACE

**Povrchová úprava:** nVent CADDY Armour;Electrogalvanized

Table 1/1

| Katalogové číslo | Article Number | Materiál             | Flange Thickness (FT) | Screw Diameter (Sc) | Screw Length (L) | Static Load |
|------------------|----------------|----------------------|-----------------------|---------------------|------------------|-------------|
| 4H24IM11         | 170140         | Spring Ocel,<br>Ocel | 3 - 8 mm              | 6                   | 11mm             | 150N        |
| 4H58IM11         | 170160         | Spring Ocel,<br>Ocel | 8 - 14 mm             | 6                   | 11mm             | 150N        |

## DIAGRAMS

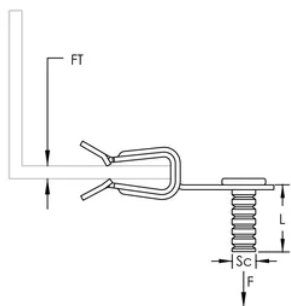

## UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na [www.nvent.com](http://www.nvent.com) a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRachte

