

Light Duty Expansion Anchor



CERTIFICATIONS



VLASTNOSTI

Ideal for use with fire rated clips and clamps

Fire resistance class R30-R120 for design of anchorages under exposure to fire

ETA assessed for anchoring in cracked and non-cracked concrete

SPECIFIKACE

Table 1/2

Katalogové číslo	Article Number	Materiál	Povrchová úprava	Drill Hole Depth	A	Drill Bit Diameter (Ø)
SCMND	800071	Ocel	Electrogalvaniz ed	45mm	5 mm Max	6"

Table 2/2

Katalogové číslo	Article Number	Hole Size (HS)
SCMND	800071	7.2 mm

DALŠÍ PODROBNOSTI O PRODUKTU


Drill Hole Depth represents the maximum depth and should be adjusted based on the thickness of product being fixed.

The maximum load per fixing point for multiple use for non-structural applications may, depending on national regulations, be below the approved load of the anchor. The approved loads per fixing point are regulated for their respective countries in the ETAG 001, Part 6.

Total safety factor as per ETAG 001 included (Y_m and Y_f).

Extract from Permissible Service Conditions of ETA-09/0313			
Multiple use for non-structural applications			
Part Number	Cracked Concrete C20/25	Non-Cracked Concrete C20/25	Standard Embedment Depth
SCMND	1.4 kN	1.4 kN	45 mm

DIAGRAMS

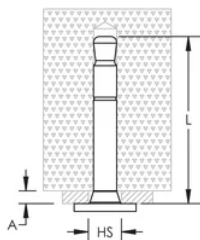

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

