

nVent CADDY Cat HP J-Hook with Multi-Function Clip



CERTIFICATIONS



VLASTNOSTI

Quick attachment to threaded rod or wire

Fully adjustable and easy to relocate to accommodate changes once installed

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

Provides superior fill capacity and load rating over most other non-continuous cable support alternatives

Rounded edges on J-Hooks provide proper bend radius support for high performance data cables

Cost effective alternative to expensive cable tray

Complies with EN 50174-2

Meets ISO®/IEC 14763-2, ANSI®/TIA 568 and ANSI®/TIA 569

Increased capability and application options by combining 4Z and 6Z products into one enhanced and efficient offering

Improved multi-function clip allows for optimized inventory while reducing job site scheduling risks associated with multiple SKUs

SPECIFIKACE

Povrchová úprava: Pregalvanized;nVent CADDY Armour

Table 1/2

Katalogové číslo	Article Number	Materiál	Diameter (Ø)	Area	Cable Capacity, Cat 5e	Cable Capacity, Cat 6
CAT21HP4Z34	181258	Ocel, Spring Ocel	33.3 mm	1174mm ²	50	40
CAT32HP4Z34	181218	Ocel, Spring Ocel	50 mm	2561mm ²	90	60
CAT16HP4Z34	181217	Ocel, Spring Ocel	25 mm	690mm ²	20	15

Table 2/2


Katalogové číslo	Article Number	Cable Capacity, Cat 6A	Velikost drátu	Rod Size (RS)	Static Load
CAT21HP4Z34	181258	25	3.9 - 4.8 mm	4, 6, 8, 10	130N
CAT32HP4Z34	181218	35	3.9 - 4.8 mm	4, 6, 8, 10	130N
CAT16HP4Z34	181217	10	3.9 - 4.8 mm	4, 6, 8, 10	130N

DALŠÍ PODROBNOSTI O PRODUKTU

Non-continuous supports may not exceed spacing of 5' (1.5 m) per TIA 569-C.9.7 and EN 50174-2.

Cable capacity is calculated based on a 70% fill rate.

DIAGRAMS

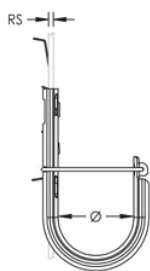

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

