

nVent CADDY Pyramid Light-Duty Equipment Support Kit Extension Frame



The nVent CADDY Pyramid Light-Duty Equipment Support Kit Extension Frame provides an efficient way to link HVAC units together. Pairing with the nVent CADDY Pyramid Light-Duty Equipment Support Kit creates an innovative system that allows contractors to quickly and easily install HVAC mini split units on rooftops. To further increase overall productivity, savings and job site safety, opt to pre-assemble the system beforehand.

VLASTNOSTI

System takes 80% less time to install than using other standard options on the market

Easily adjusts from 12 -18 in (305 -457 mm), reducing the need for multiple SKUs

Increased adjustability enables flexibility to move bars, sliding the kit as needed

Extension Kit allows for pre-assembly and endless gang-ability of units linked together

Extension Kit is 8.4 in (213 mm) longer than four-post kit to allow for mounted equipment to be serviced in place

Evenly distributes load and avoids damaging roof membrane with nVent CADDY PEK-style foam bottom feet

Product load rating can handle a wide range of equipment BTU outputs/sizes

Hot dip galvanized construction and hardware provide superior corrosion resistance in demanding environments

SPECIFIKACE

Table 1/3

Katalogové číslo	Article Number	Materiál	Povrchová úprava	Temperature	Height (H)	Length (L)
PEKLDEF	360531	Ocel	Hot-Dip Galvanized	-34.4 to 54.4 °C	305 - 457 mm	1265mm


Table 2/3

Katalogové číslo	Article Number	Post Base (A)	Square Tube (B)	Cross Bar Assembly (C)	Width (W)	Surface Area
PEKLDEF	360531	152 mm x 2 pc	1224.28 mm x 2 pc	521 mm x 2 pc	660 mm	0.046m ²

Table 3/3

Katalogové číslo	Article Number	Unit Weight	Ultimate Static Load (F)	Static Load Safety Factor
PEKLDEF	360531	11.5 kg	1779N	3:1

DIAGRAMS

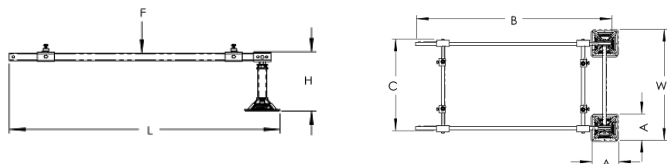

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

