

nVent CADDY Rod Lock Channel Nut



CERTIFICATIONS



VLASTNOSTI

Provides fast universal attachment of threaded rod and hardware to standard strut profiles

Can be used to prefabricate assemblies which can be quickly pushed onto previously installed threaded rods

Works with slightly damaged threads and minor burrs on the threaded rod

SPECIFIKACE

Materiál: Cast Iron
Povrchová úprava: Electrogalvanized


Table 1/2

Katalogové číslo	Article Number	Rod Size (RS)	B	C	D	Length (L)
CRLSM10EG	390004	10	35 mm	19.5 mm	13.5 mm	23mm
CRLSM8EG	390003	8	35 mm	19.5 mm	13.5 mm	23mm

Table 2/2

Katalogové číslo	Article Number	Static Load
CRLSM10EG	390004	3750N
CRLSM8EG	390003	2750N

DIAGRAMS

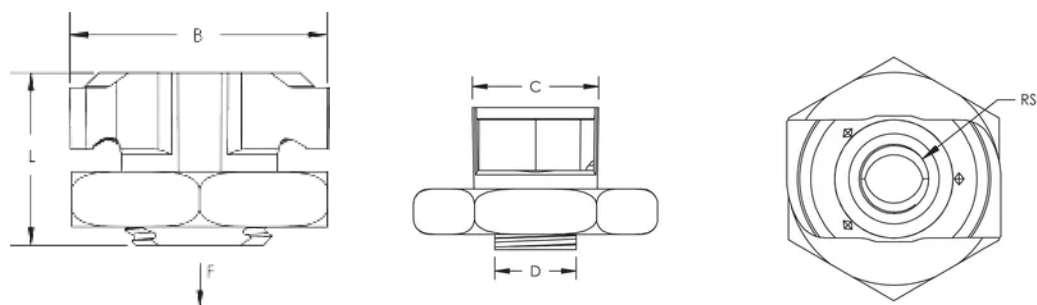

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

