


nVent CADDY Speed Link SLK with Toggle



CERTIFICATIONS

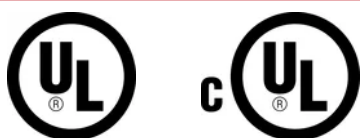

VLASTNOSTI

Complete system includes wire, locking device and pre-assembled toggle end fitting

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

Also available in Y-toggle configuration

SPECIFIKACE

Wire Rope Diameter:	1.5 mm
Static Load Safety Factor:	5:1
Povrchová úprava:	Electrogalvanized
Complies With:	SMACNA HVAC-DCS

Table 1/1

Katalogové číslo	Article Number	Materiál	Wire Rope Length	A	B	Static Load
SLK15L10T	196526	Steel, Zinc Alloy, Polypropylene	10m	39 mm	5 mm	195N

Katalogové číslo	Article Number	Materiál	Wire Rope Length	A	B	Static Load
SLK15L1T	196521	Steel, Zinc Alloy, Polypropylene	1m	39 mm	5 mm	195N
SLK15L2T	196522	Steel, Zinc Alloy, Polypropylene	2m	39 mm	5 mm	195N
SLK15L2TR2	196644	Steel, Zinc Alloy, Polypropylene	2m	39 mm	5 mm	195N
SLK15L3T	196523	Steel, Zinc Alloy, Polypropylene	3m	39 mm	5 mm	195N
SLK15L5T	196524	Steel, Zinc Alloy, Polypropylene	5m	39 mm	5 mm	195N
SLK15L7T	196525	Steel, Zinc Alloy, Polypropylene	7m	39 mm	5 mm	195N


Thickness (T): 12.5 mm

Width (W): 19 mm

Height (H): 55 mm

Angle (a): 90 ° Max

DIAGRAMS

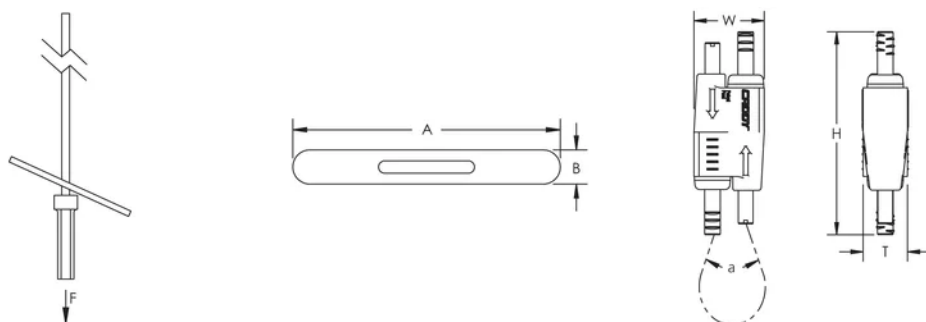

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

