


nVent CADDY Speed Link SLS with Decking Hook



CERTIFICATIONS

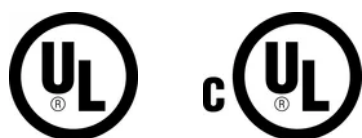

VLASTNOSTI

Complete system includes wire, locking device and pre-assembled decking hook end fitting

Quickly and easily attaches to hollow metal decking

Spring-loaded ends snap into decking hole and lock into place

Innovative design helps protect the wire from sharp edges of decking hole, minimizing risk of damage to wire

Finger tightening of nut secures the locking device into position without tools

Installs in strut profiles without the need to insert fingers or tools into the strut

SPECIFIKACE

Wire Rope Diameter:	2 mm
Static Load Safety Factor:	5:1
Povrchová úprava:	Electrogalvanized
Complies With:	SMACNA HVAC-DCS

Table 1/2

Katalogové číslo	Article Number	Materiál	Wire Rope Length	Roof Decking Sheet Thickness	A	Hole Size 1 (HS1)
SLS2L3DH	196753	Steel, Zinc Alloy, Polypropylene	3m	1.5 mm Max	9.2 mm	8 mm
SLS2L5DH	196754	Steel, Zinc Alloy, Polypropylene	5m	1.5 mm Max	9.2 mm	8 mm

Table 2/2

Katalogové číslo	Article Number	Static Load
SLS2L3DH	196753	270N
SLS2L5DH	196754	270N

Slot Size (SS): 8 x 6.5 mm - 8 x 10 mm

Hole Size 2 (HS2): 8 - 10 mm

Width (W): 16 mm

Height 2 (H2): 46.5mm

Height 1 (H1): 53mm

Thread Size (TS): M8

Thickness (T): 4 mm Max

DALŠÍ PODROBNOSTI O PRODUKTU


The 2 mm locking device is compatible with C-Channel Types E0 and E0L.

Total load per wire on a multi-tier trapeze must not exceed static load.

Load rating is only applicable if the load-bearing capacity of the supporting element (steel decking) is adequate.

Check with deck manufacturer for recommended load capacity.

DIAGRAMS

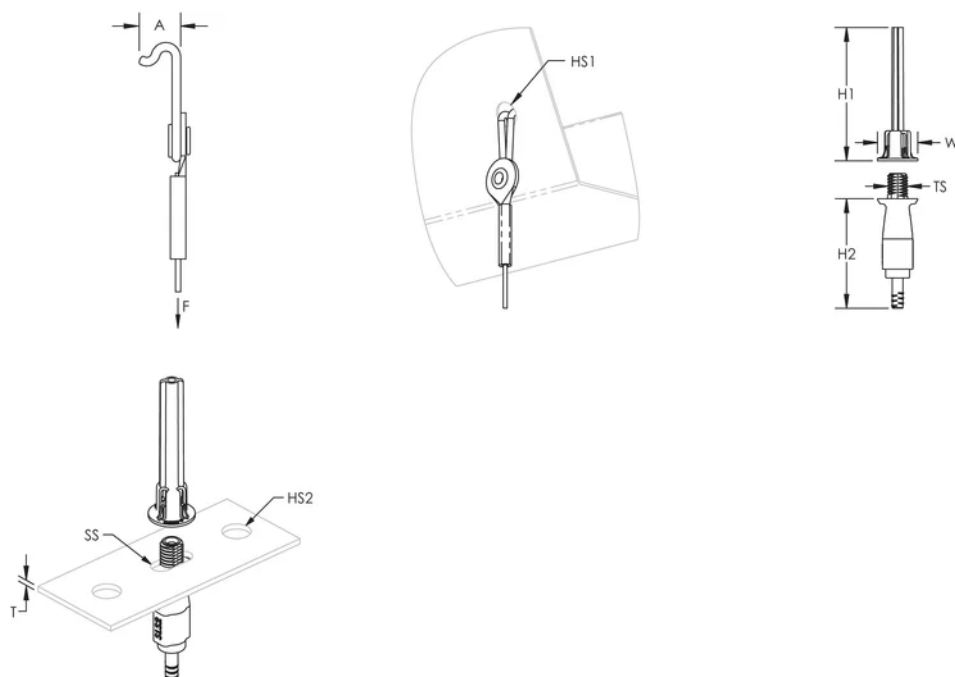

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

