

PEMSA Wire Basket Tray



The PEMS A Wire Basket Tray is the backbone of PEMS A Wire Basket Tray System. Highly engineered features help ensure a secure installation that complies with industry codes and standards for high-performance cables. Clever design allows the installer to maximize field efficiency with the Rejiband Rapide Integrated Splice.

CERTIFICATIONS



VLASTNOSTI

Provides optimal support for high-performance low voltage and data cables

Innovative Rejiband Rapide installation system

IEC 61537 load rating and earthing compliant

Responsive design and layout services, including seismic

SPECIFIKACE

Table 1/2

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT35X60S4	821003		Stainless Steel 304 (EN 1.4301)		3000mm	35 mm
WBT35X60BA	821001	Black	Carbon Steel	Strukturovaný Práškový	3000mm	35 mm
WBT35X60EG	821000		Carbon Steel	Electrogalvaniz ed	3000mm	35 mm

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT35X100BA	821011	Black	Carbon Steel	Strukturovaný Práškový	3000mm	35 mm
WBT35X100EG	821010		Carbon Steel	Electrogalvaniz ed	3000mm	35 mm
WBT35X100S4	821013		Stainless Steel 304 (EN 1.4301)		3000mm	35 mm
WBT35X150BA	821021	Black	Carbon Steel	Strukturovaný Práškový	3000mm	35 mm
WBT35X150EG	821020		Carbon Steel	Electrogalvaniz ed	3000mm	35 mm
WBT35X150S4	821023		Stainless Steel 304 (EN 1.4301)		3000mm	35 mm
WBT35X200BA	821031	Black	Carbon Steel	Strukturovaný Práškový	3000mm	35 mm
WBT35X200EG	821030		Carbon Steel	Electrogalvaniz ed	3000mm	35 mm
WBT35X200S4	821033		Stainless Steel 304 (EN 1.4301)		3000mm	35 mm
WBT35X300BA	821041	Black	Carbon Steel	Strukturovaný Práškový	3000mm	35 mm
WBT35X300EG	821040		Carbon Steel	Electrogalvaniz ed	3000mm	35 mm
WBT35X300S4	821043		Stainless Steel 304 (EN 1.4301)		3000mm	35 mm
WBT35X400BA	821051	Black	Carbon Steel	Strukturovaný Práškový	3000mm	35 mm
WBT35X400EG	821050		Carbon Steel	Electrogalvaniz ed	3000mm	35 mm
WBT35X400S4	821053		Stainless Steel 304 (EN 1.4301)		3000mm	35 mm
WBT60X60BA	820001	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60 mm
WBT60X60BG	820002	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60 mm

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT60X60EG	820000		Carbon Steel	Electrogalvaniz ed	3000mm	60 mm
WBT60X60S4	820003		Stainless Steel 304 (EN 1.4301)		3000mm	60 mm
WBT60X300BG	820042	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60 mm
WBT60X300EG	820040		Carbon Steel	Electrogalvaniz ed	3000mm	60 mm
WBT60X300S4	820043		Stainless Steel 304 (EN 1.4301)		3000mm	60 mm
WBT60X400BA	820051	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60 mm
WBT60X400BG	820052	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60 mm
WBT60X400EG	820050		Carbon Steel	Electrogalvaniz ed	3000mm	60 mm
WBT60X400S4	820053		Stainless Steel 304 (EN 1.4301)		3000mm	60 mm
WBT60X450BA	820081	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60 mm
WBT60X450BG	820082	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60 mm
WBT60X450EG	820080		Carbon Steel	Electrogalvaniz ed	3000mm	60 mm
WBT60X450S4	820083		Stainless Steel 304 (EN 1.4301)		3000mm	60 mm
WBT60X500BA	820061	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60 mm
WBT60X500BG	820062	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60 mm
WBT60X500EG	820060		Carbon Steel	Electrogalvaniz ed	3000mm	60 mm
WBT60X500S4	820063		Stainless Steel 304 (EN 1.4301)		3000mm	60 mm

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT60X600BA	820075	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60 mm
WBT60X600BG	820076	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60 mm
WBT60X600EG	820074		Carbon Steel	Electrogalvaniz ed	3000mm	60 mm
WBT60X600S4	820077		Stainless Steel 304 (EN 1.4301)		3000mm	60 mm
WBT60X100BA	820011	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60 mm
WBT60X100BG	820012	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60 mm
WBT60X100EG	820010		Carbon Steel	Electrogalvaniz ed	3000mm	60 mm
WBT60X100S4	820013		Stainless Steel 304 (EN 1.4301)		3000mm	60 mm
WBT60X150BA	820021	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60 mm
WBT60X150BG	820022	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60 mm
WBT60X150EG	820020		Carbon Steel	Electrogalvaniz ed	3000mm	60 mm
WBT60X150S4	820023		Stainless Steel 304 (EN 1.4301)		3000mm	60 mm
WBT60X200BA	820031	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60 mm
WBT60X200BG	820032	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60 mm
WBT60X200EG	820030		Carbon Steel	Electrogalvaniz ed	3000mm	60 mm
WBT60X200S4	820033		Stainless Steel 304 (EN 1.4301)		3000mm	60 mm
WBT60X300BA	820041	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60 mm

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT100X100B A	823011	Black	Carbon Steel	Strukturovaný Práškový	3000mm	100 mm
WBT100X100B G	823012	Black	Carbon Steel	Electrogalvaniz ed	3000mm	100 mm
WBT100X100E G	823010		Carbon Steel	Electrogalvaniz ed	3000mm	100 mm
WBT100X100S 4	823013		Stainless Steel 304 (EN 1.4301)		3000mm	100 mm
WBT100X150B A	823021	Black	Carbon Steel	Strukturovaný Práškový	3000mm	100 mm
WBT100X150B G	823022	Black	Carbon Steel	Electrogalvaniz ed	3000mm	100 mm
WBT100X150E G	823020		Carbon Steel	Electrogalvaniz ed	3000mm	100 mm
WBT100X150S 4	823023		Stainless Steel 304 (EN 1.4301)		3000mm	100 mm
WBT100X200B A	823031	Black	Carbon Steel	Strukturovaný Práškový	3000mm	100 mm
WBT100X200B G	823032	Black	Carbon Steel	Electrogalvaniz ed	3000mm	100 mm
WBT100X200E G	823030		Carbon Steel	Electrogalvaniz ed	3000mm	100 mm
WBT100X200S 4	823033		Stainless Steel 304 (EN 1.4301)		3000mm	100 mm
WBT100X300B A	823041	Black	Carbon Steel	Strukturovaný Práškový	3000mm	100 mm

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT100X300B G	823042	Black	Carbon Steel	Electrogalvaniz ed	3000mm	100 mm
WBT100X300E G	823040		Carbon Steel	Electrogalvaniz ed	3000mm	100 mm
WBT100X300S 4	823043		Stainless Steel 304 (EN 1.4301)		3000mm	100 mm
WBT100X400B A	823051	Black	Carbon Steel	Strukturovaný Práškový	3000mm	100 mm
WBT100X400B G	823052	Black	Carbon Steel	Electrogalvaniz ed	3000mm	100 mm
WBT100X400E G	823050		Carbon Steel	Electrogalvaniz ed	3000mm	100 mm
WBT100X400S 4	823053		Stainless Steel 304 (EN 1.4301)		3000mm	100 mm
WBT100X450B A	823081	Black	Carbon Steel	Strukturovaný Práškový	3000mm	100 mm
WBT100X450B G	823082	Black	Carbon Steel	Electrogalvaniz ed	3000mm	100 mm
WBT100X450E G	823080		Carbon Steel	Electrogalvaniz ed	3000mm	100 mm
WBT100X450S 4	823083		Stainless Steel 304 (EN 1.4301)		3000mm	100 mm
WBT100X500B A	823061	Black	Carbon Steel	Strukturovaný Práškový	3000mm	100 mm
WBT100X500B G	823062	Black	Carbon Steel	Electrogalvaniz ed	3000mm	100 mm

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT100X500E G	823060		Carbon Steel	Electrogalvaniz ed	3000mm	100 mm
WBT100X500S 4	823063		Stainless Steel 304 (EN 1.4301)		3000mm	100 mm
WBT100X600B A	823071	Black	Carbon Steel	Strukturovaný Práškový	3000mm	100 mm
WBT100X600B G	823072	Black	Carbon Steel	Electrogalvaniz ed	3000mm	100 mm
WBT100X600E G	823070		Carbon Steel	Electrogalvaniz ed	3000mm	100 mm
WBT100X600S 4	823073		Stainless Steel 304 (EN 1.4301)		3000mm	100 mm
WBT150X200B A	825031	Black	Carbon Steel	Strukturovaný Práškový	3000mm	150 mm
WBT150X200B G	825032	Black	Carbon Steel	Electrogalvaniz ed	3000mm	150 mm
WBT150X200E G	825030		Carbon Steel	Electrogalvaniz ed	3000mm	150 mm
WBT150X200S 4	825033		Stainless Steel 304 (EN 1.4301)		3000mm	150 mm
WBT150X300B A	825041	Black	Carbon Steel	Strukturovaný Práškový	3000mm	150 mm
WBT150X300B G	825042	Black	Carbon Steel	Electrogalvaniz ed	3000mm	150 mm
WBT150X300E G	825040		Carbon Steel	Electrogalvaniz ed	3000mm	150 mm

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT150X300S 4	825043		Stainless Steel 304 (EN 1.4301)		3000mm	150 mm
WBT150X400B A	825051	Black	Carbon Steel	Strukturovaný Práškový	3000mm	150 mm
WBT150X400B G	825052	Black	Carbon Steel	Electrogalvaniz ed	3000mm	150 mm
WBT150X400E G	825050		Carbon Steel	Electrogalvaniz ed	3000mm	150 mm
WBT150X400S 4	825053		Stainless Steel 304 (EN 1.4301)		3000mm	150 mm
WBT150X450B A	825081	Black	Carbon Steel	Strukturovaný Práškový	3000mm	150 mm
WBT150X450B G	825082	Black	Carbon Steel	Electrogalvaniz ed	3000mm	150 mm
WBT150X450E G	825080		Carbon Steel	Electrogalvaniz ed	3000mm	150 mm
WBT150X450S 4	825083		Stainless Steel 304 (EN 1.4301)		3000mm	150 mm
WBT150X500B A	825061	Black	Carbon Steel	Strukturovaný Práškový	3000mm	150 mm
WBT150X500B G	825062	Black	Carbon Steel	Electrogalvaniz ed	3000mm	150 mm
WBT150X500E G	825060		Carbon Steel	Electrogalvaniz ed	3000mm	150 mm
WBT150X500S 4	825063		Stainless Steel 304 (EN 1.4301)		3000mm	150 mm

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT150X600B A	825071	Black	Carbon Steel	Strukturovaný Práškový	3000mm	150 mm
WBT150X600B G	825072	Black	Carbon Steel	Electrogalvaniz ed	3000mm	150 mm
WBT150X600E G	825070		Carbon Steel	Electrogalvaniz ed	3000mm	150 mm
WBT150X600S 4	825073		Stainless Steel 304 (EN 1.4301)		3000mm	150 mm
WBT150X900B A	825091	Black	Carbon Steel	Strukturovaný Práškový	3000mm	150 mm
WBT150X900B G	825092	Black	Carbon Steel	Electrogalvaniz ed	3000mm	150 mm
WBT150X900E G	825090		Carbon Steel	Electrogalvaniz ed	3000mm	150 mm
WBT150X900S 4	825093		Stainless Steel 304 (EN 1.4301)		3000mm	150 mm

Table 2/2

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT35X60S4	821003	60 mm	1.19 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X60BA	821001	60 mm	1.2 kg	
WBT35X60EG	821000	60 mm	1.2 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X100BA	821011	100 mm	1.62 kg	
WBT35X100EG	821010	100 mm	1.62 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT35X100S4	821013	100 mm	1.61 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X150BA	821021	150 mm	1.76 kg	
WBT35X150EG	821020	150 mm	1.76 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT35X150S4	821023	150 mm	2.12 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X200BA	821031	200 mm	2.5 kg	
WBT35X200EG	821030	200 mm	2.5 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT35X200S4	821033	200 mm	3.04 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X300BA	821041	300 mm	3.42 kg	
WBT35X300EG	821040	300 mm	3.42 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT35X300S4	821043	300 mm	4.13 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X400BA	821051	400 mm	4.29 kg	
WBT35X400EG	821050	400 mm	4.29 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT35X400S4	821053	400 mm	5.22 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X60BA	820001	60 mm	2.32 kg	

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT60X60BG	820002	60 mm	2.32 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X60EG	820000	60 mm	2.32 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT60X60S4	820003	60 mm	2.32 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X300BG	820042	300 mm	5.13 kg	DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X300EG	820040	300 mm	5.13 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT60X300S4	820043	300 mm	5.13 kg	DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X400BA	820051	400 mm	6.21 kg	
WBT60X400BG	820052	400 mm	6.21 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT60X400EG	820050	400 mm	6.21 kg	DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X400S4	820053	400 mm	6.21 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT60X450BA	820081	450 mm	6.39 kg	

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT60X450BG	820082	450 mm	6.39 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X450EG	820080	450 mm	6.39 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT60X450S4	820083	450 mm	6.39 kg	
WBT60X500BA	820061	500 mm	7.35 kg	
WBT60X500BG	820062	500 mm	7.35 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT60X500EG	820060	500 mm	7.35 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X500S4	820063	500 mm	7.35 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X600BA	820075	600 mm	8.43 kg	
WBT60X600BG	820076	600 mm	8.43 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT60X600EG	820074	600 mm	8.43 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X600S4	820077	600 mm	8.43 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT60X100BA	820011	100 mm	2.43 kg	

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT60X100BG	820012	100 mm	2.43 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT60X100EG	820010	100 mm	2.43 kg	DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X100S4	820013	100 mm	2.43 kg	DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X150BA	820021	150 mm	2.6 kg	
WBT60X150BG	820022	150 mm	2.6 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT60X150EG	820020	150 mm	2.6 kg	DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X150S4	820023	150 mm	2.6 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT60X200BA	820031	200 mm	3.33 kg	
WBT60X200BG	820032	200 mm	3.33 kg	DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X200EG	820030	200 mm	3.33 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT60X200S4	820033	200 mm	3.33 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT60X300BA	820041	300 mm	5.13 kg	
WBT100X100BA	823011	100 mm	3.27 kg	
WBT100X100BG	823012	100 mm	3.27 kg	DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X100EG	823010	100 mm	3.27 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X100S4	823013	100 mm	3.27 kg	DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X150BA	823021	150 mm	3.45 kg	
WBT100X150BG	823022	150 mm	3.45 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X150EG	823020	150 mm	3.45 kg	DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X150S4	823023	150 mm	3.45 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X200BA	823031	200 mm	4.14 kg	


Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT100X200BG	823032	200 mm	4.14 kg	DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X200EG	823030	200 mm	4.14 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X200S4	823033	200 mm	4.14 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X300BA	823041	300 mm	6.15 kg	
WBT100X300BG	823042	300 mm	6.15 kg	DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X300EG	823040	300 mm	6.15 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X300S4	823043	300 mm	6.15 kg	DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X400BA	823051	400 mm	7.23 kg	
WBT100X400BG	823052	400 mm	7.23 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X400EG	823050	400 mm	7.23 kg	DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT100X400S4	823053	400 mm	7.23 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X450BA	823081	450 mm	7.44 kg	
WBT100X450BG	823082	450 mm	7.44 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X450EG	823080	450 mm	7.44 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X450S4	823083	450 mm	7.44 kg	
WBT100X500BA	823061	500 mm	8.34 kg	
WBT100X500BG	823062	500 mm	8.34 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X500EG	823060	500 mm	8.34 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X500S4	823063	500 mm	8.34 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X600BA	823071	600 mm	9.42 kg	
WBT100X600BG	823072	600 mm	9.42 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X600EG	823070	600 mm	9.42 kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, UKCA, CADDY EU WBT

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT100X600S4	823073	600 mm	9.42 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT150X200BA	825031	200 mm	6.01 kg	
WBT150X200BG	825032	200 mm	6.01 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X200EG	825030	200 mm	6.01 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT
WBT150X200S4	825033	200 mm	6.01 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X300BA	825041	300 mm	7.29 kg	
WBT150X300BG	825042	300 mm	7.29 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X300EG	825040	300 mm	7.29 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT
WBT150X300S4	825043	300 mm	7.29 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X400BA	825051	400 mm	8.47 kg	
WBT150X400BG	825052	400 mm	8.47 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X400EG	825050	400 mm	8.47 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT, DoP, CADDY EU WBT
WBT150X400S4	825053	400 mm	8.47 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X450BA	825081	450 mm	8.68 kg	
WBT150X450BG	825082	450 mm	8.68 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X450EG	825080	450 mm	8.68 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X450S4	825083	450 mm	8.68 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT150X500BA	825061	500 mm	9.7 kg	
WBT150X500BG	825062	500 mm	9.7 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X500EG	825060	500 mm	9.7 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X500S4	825063	500 mm	9.7 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X600BA	825071	600 mm	10.65 kg	
WBT150X600BG	825072	600 mm	10.65 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X600EG	825070	600 mm	10.65 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X600S4	825073	600 mm	10.65 kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X900BA	825091	900 mm	15.98 kg	
WBT150X900BG	825092	900 mm	15.98 kg	
WBT150X900EG	825090	900 mm	15.98 kg	
WBT150X900S4	825093	900 mm	15.98 kg	

DIAGRAMS

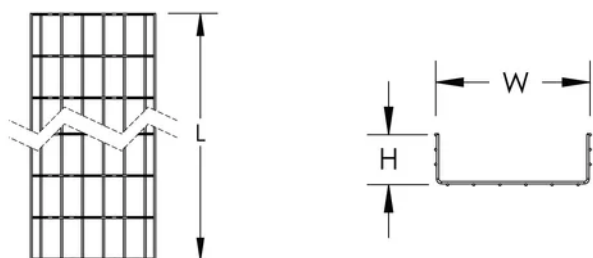

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit

selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

