

Speedway Cable Ladder Flat Elbow, 90°



CERTIFICATIONS



VLASTNOSTI

Creates a 90° corner change in cable tray direction

Provides optimal support for high-performance low voltage and data cables

Innovative SPEEDLOK integrated coupling system

Safety edge protects cables during installation

Slotted side channel, eliminating field drilling for cut-to-length applications

IEC 61537 load rating and earthing compliant

Responsive design and layout services, including seismic

SPECIFIKACE

Povrchová úprava: Hot-Dip Galvanized


Materiál: Ocel

Table 1/1

Katalogové číslo	Article Number	Width (W)	Angle (a)	A	B	C
------------------	----------------	-----------	-----------	---	---	---

CL110X900FE9 OHD	840250	900 mm	90 °	1295 mm	1295 mm	80 mm
CL110X600FE9 OHD	840230	600 mm	90 °	995 mm	995 mm	80 mm
CL110X750FE9 OHD	840240	750 mm	90 °	1145 mm	1145 mm	80 mm
CL110X450FE9 OHD	840220	450 mm	90 °	845 mm	845 mm	80 mm
CL110X150FE9 OHD	840200	150 mm	90 °	545 mm	545 mm	80 mm
CL110X300FE9 OHD	840210	300 mm	90 °	695 mm	695 mm	80 mm

DIAGRAMS

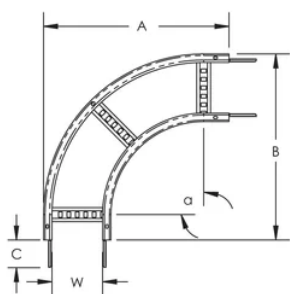

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

