


19" Front Panel, Vented

Data Solutions

Vented front panels allows heat dissipation through holes.

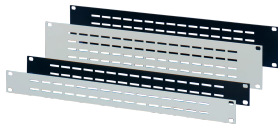

CERTIFICATIONS



VLASTNOSTI

Vented front panels (Aluminum) allows heat dissipation

SPECIFIKACE

Rack Width:	95HP
Materiál:	Hliník
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/2

Katalogové číslo	Rack Height	Povrchová úprava	Mounting	Množství v balení	Front Finish	Rear Finish
30118-962	1U	Strukturovaný Práškový	Screw-on Front	1	Painted	Painted

Katalogové číslo	Rack Height	Povrchová úprava	Mounting	Množství v balení	Front Finish	Rear Finish
30702-044	1U	Anodized	Screw-on Front	1	Raw	Conductive
30702-047	1U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-056	1U	Strukturovaný Práškový	Screw-on Front	1	Painted	Painted
30118-963	2U	Anodized	Screw-on Front	1	Painted	Painted
30702-045	2U	Anodized	Screw-on Front	1	Raw	Raw
30702-048	2U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-057	2U	Strukturovaný Práškový	Screw-on Front	1	Painted	Painted
30118-964	3U	Strukturovaný Práškový	Screw-on Front	1	Painted	Painted
30702-046	3U	Anodized	Screw-on Front	1	Raw	Raw
30702-049	3U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-058	3U	Strukturovaný Práškový	Screw-on Front	1	Painted	Painted

Table 2/2						
Katalogové číslo	Treated Edges	Kód barvy	EMC Shielding	Výška (H)	Typ	Šířka (W)
30118-962		RAL 7021	No	43.6mm	19" Front Panel	483mm
30702-044			No	43.6mm	19" Front Panel	483mm
30702-047	Yes		No	43.6mm	19" Front Panel	483mm
30702-056		RAL 7035	No	43.6mm	19" Front Panel	483mm
30118-963		RAL 7021	No	88.1mm	19" Front Panel	483mm



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE