

Branch Line Restraint Structure Attachment to Wood/Concrete

Data Solutions



CERTIFICATIONS



VLASTNOSTI

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to wood or concrete where cracked concrete approval is not needed

SPECIFIKACE

Table 1/2

Katalogové číslo	Article Number	Materiál	Povrchová úprava	Rod Size (RS)	Height (H)	Length (L)
CSBBRS2MEG	402240	Ocel	Electrogalvaniz ed	10, 12	28.2mm	40.4mm

Table 2/2


Katalogové číslo	Article Number	Width (W)	Screw Length (L)	Drill Bit Diameter
------------------	----------------	-----------	------------------	--------------------

CSBBRS2MEG	402240	26.9mm	44.5mm	5mm
------------	--------	--------	--------	-----

DALŠÍ PODROBNOSTI O PRODUKTU

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

DIAGRAMS

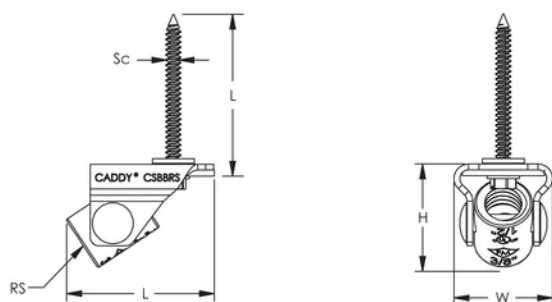

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE