

Low Voltage Insulators, Metric Thread, 20 mm, 17 mm Hex Width, M4 Thread

Data Solutions

KATALOGOVÉ ČÍSLO

ISOTP20M4



CERTIFICATIONS



VLASTNOSTI

Halogen free

High resistance to leakage current

Great stability of electrical and mechanical parameters

Fiberglass reinforced

UL® Recognized in E125470 and evaluated for dielectric withstand rating of 1,500 VAC/DC

RoHS compliant

VLASTNOSTI PRODUKTU

Article Number: 548410

Materiál: Ocel; Glass Fibre Reinforced Polyamide

Povrchová úprava: Electrogalvanized

Working Temperature: -40 to 130°C

Flammability Rating: UL® 94V-0

Complies With: IEC® 60695-2-11 (Glow Wire Test 960 °C)

Dielectric Strength, IEC 61439.1: 3500 VAC @ 1 min

Dielectric Strength, UL: 1500

Insulation Voltage: 1000; 1500

Height (H): 20mm

Hex Width (W): 17mm

Hloubka (D): 20mm

Thread Size (TS): M4

Thread Depth (TD): 4mm

Diameter (Ø): 15mm

Static Load 1 (F1): 150daN


Static Load 2 (F2): 100daN

Unit Weight: 0.01kg

DALŠÍ PODROBNOSTI O PRODUKTU

Creepage and clearance distances need to be in accordance with the relevant application standard.

DIAGRAMS

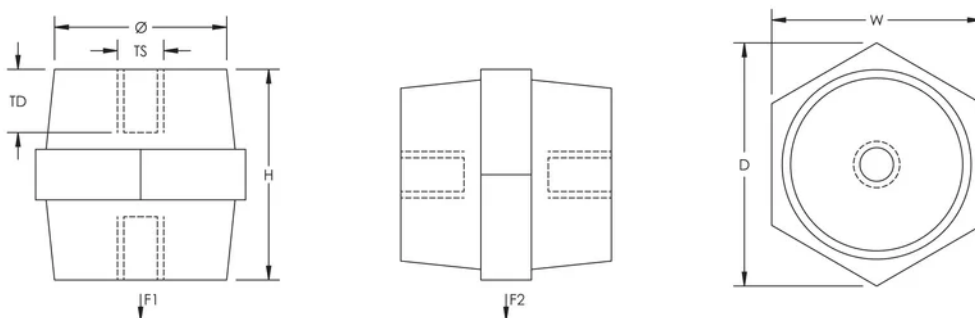

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE