


Joint Bond T8 Complete Welder Pair, Power, 50 mm² Ropelay

Data Solutions

KATALOGOVÉ ČÍSLO

PBCT8X3

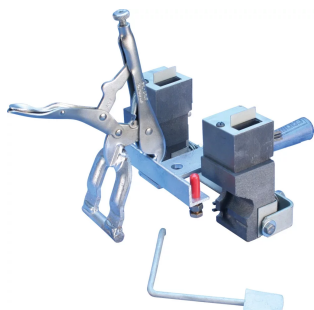

VLASTNOSTI

Complete welder assembly provides a convenient means of attaching jumper bonds to the head of the rail

Connection is made within the confines of the splice plate

Includes mold cleaner and flint ignitor

VLASTNOSTI PRODUKTU

Material: Graphite; Ocel; Thermoplastic

Rail Type: 85 lb to 141 lb T-Rail Sections

Bond Terminal Style: C

Conductor Size: 50 mm² Ropelay

Conductor Outer Diameter, Nominal: 9.13mm

Bond Length: 177.8mm

Welder Style: T8

Mold Only: No

Replacement Mold: PBCX3

Welding Material: PB45, Sold Separately

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE