

Stud to Web of Rail Kit, RI52, RI59, 49.27 mm, 9.5 mm dia, 3/8 UNC Thread

Data Solutions

KATALOGOVÉ ČÍSLO

PBK244



VLASTNOSTI

Provides material to directly connect studs to the neutral axis of the rail web utilizing the exothermic process

Kits include an nVent ERICO Cadweld mold allocation, mold cleaning tool, flint ignitor, studs, washers and nuts

VLASTNOSTI PRODUKTU

Materiál: Graphite; Silicon Bronze; Stainless Steel 302 (EN 1.4324); Stainless Steel 304 (EN 1.4301)

Rail Type: RI52; RI59

Number of Connections: 1

Minimum Order Quantity: 50

Mold Family: HV Mold Family

Length (L): 49.27mm

Diameter (Ø): 9.5mm

Thread Size (TS): 3/8" UNC

Studs: Stainless Steel (1)

Washers: 3/8" Silicon Bronze Lock Washer (1)

Nuts: 3/8"-16 UNC Silicon Bronze Hex Nut (1)

Mold Only: No

Replacement Mold: PBHV12A003

Welding Material: PB65, Sold Separately

Handle Clamp: L160, Sold Separately


Kit: Yes

DALŠÍ PODROBNOSTI O PRODUKTU

Welder frame sold separately.

A gap between conductors may be required. See mold tag for more information.

DIAGRAMS

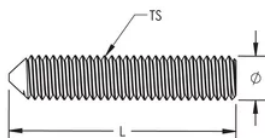

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE