

Telecom Main Grounding Busbar, Tinned, 610 mm


Data Solutions

KATALOGOVÉ ČÍSLO

TMGBA24L33PT



CERTIFICATIONS

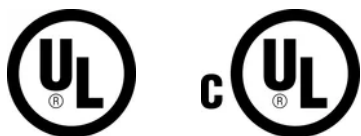

VLASTNOSTI

Meets TIA-607-C and TIA-607-D and conforms to BICSI® recommendations

Complies with NEMA® standards

Accepts two hole lugs with 5/16" or 7/16" bolt holes (hardware not included)

Telecom grounding busbar splice kits are available to extend the length of the busbar

VLASTNOSTI PRODUKTU

Materiál: Copper

Tin Plating: Yes

Width (W): 101.6mm

Thickness (T): 6.35mm

Length 1 (L1): 610mm

Length 2 (L2): 457mm

Hole Size 1 (HS1): 0.3125in

Hole Size 1 Number of Pairs: 33

Hole Size 2 (HS2): 0.4375in

Hole Size 2 Number of Pairs: 5


A: 25.4mm

B: 28.6mm

C: 15.9mm

D: 15.9mm

DIAGRAMS

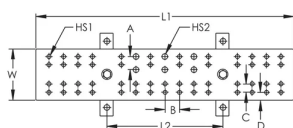

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE