

Four Pole Distrib. Block with Threaded Bars, Flat, 400 A

Data Solutions

KATALOGOVÉ ČÍSLO

TRC-400A



CERTIFICATIONS



VLASTNOSTI

Transparent protection cover

Bolts included for output connections

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

VLASTNOSTI PRODUKTU

Article Number: 563180

Materiál: Copper; Glass Fibre Reinforced Polyamide; Plexiglass

Max Working Voltage, IEC (Ui): 1000

Peak Short Circuit Current (I_{pk}): 118kA

Short Term Withstand Current (I_{cw}) 1s: 28kA

Line Side Number of Connections: 1

Load Side Number of Connections: 10

Thread Size 1 (TS1): M6

Thread Size 2 (TS2): M10

Hloubka (D): 50mm

Height (H): 338 – 390mm

Width (W): 260mm

A: 290mm

Unit Weight: 2.65kg

Flammability Rating: UL® 94V-0


Complies With: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)

DALŠÍ PODROBNOSTI O PRODUKTU

Thread Size 2 represents input plug.

Line side and load side number of connections are per pole.

DIAGRAMS

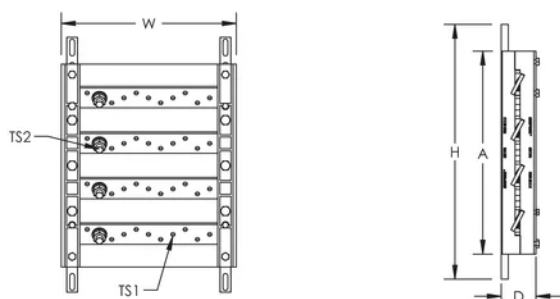

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE