


MS PDU, 2U, 60A(48A)NA/60A Int, 380-415V, 3P Wye, 9 CB, (9)C13, (9)4-in-1

Data Solutions

KATALOGOVÉ ČÍSLO

EN2954

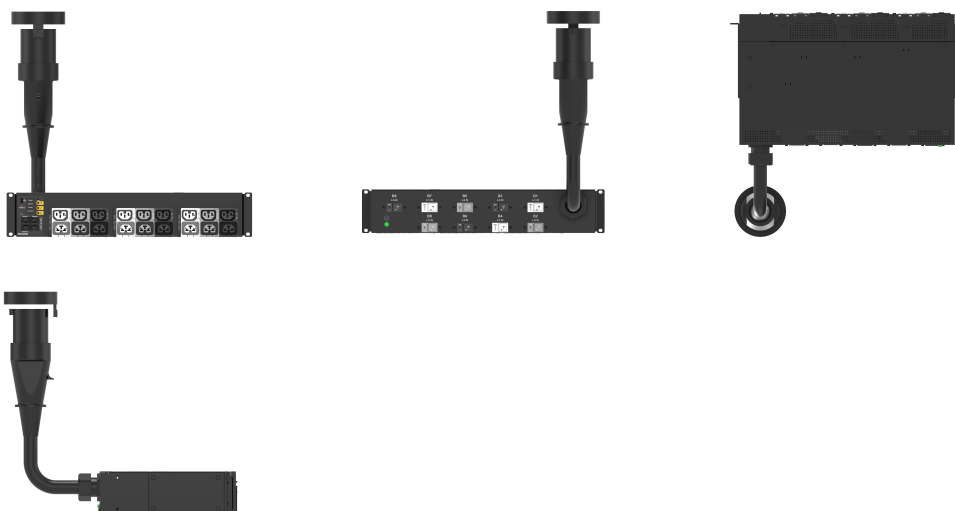

The Advantage Series Input Metered, Outlet Switched PDU family offers energy metering with advanced power and environmental monitoring options and remote outlet on/off switching. Comprehensive monitoring at both the input phase and circuit breaker levels offers advanced alerts of potential overloads. Billing-grade metering provides accurate power consumption data for energy use optimization. The hot-swappable network management controller features Gigabit and redundant ethernet communication with advanced support for external environmental sensors and rack security access solutions.

VLASTNOSTI PRODUKTU

Produktová řada: Enlogic

Product Type: Socket Strip

Typ zásuvky: (9) C13/C15; (9) C13/C15/C19/C21

Barva: Black

Circuit Breaker: 20 A

Switched Outlets: Yes

Circuit Breaker Quantity: 9

Length: 87mm

Power Rating: 34.6 kVA North America; 41.4 kVA International

Number of Poles: 1

Input Voltage: 380 – 415V

Phase: 3 PH

Output Voltage: 208 – 230VAC

Plug Type: IEC 60309 560P6 (IP44)

Nominální napětí: 415V

Removable Input Cable: No

Amperage (Derated Amperage): 60 A (48 A) North America; 60 A International

Rack Units: 2U

Typ: Intelligent PDU

Povrchová úprava: Strukturovaný Práškový

Materiál: Ocel

Výška: 87mm

Šířka: 444mm

Hloubka: 269mm

Hmotnost: 9kg

Množství v balení: 1

Input Cable Length: 1.8m

DALŠÍ PODROBNOSTI O PRODUKTU

87 mm L x 444 mm W x 269 mm D, (269 mm D at CB)

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE