

nVent ERIFLEX Flexbus HCBC Plate

Data Solutions



CERTIFICATIONS



VLASTNOSTI

Rigid tinned copper part provides strong electrical contact to maintain braid expansion during compression

HCBC Plate allows Flexbus Conductor insulation to overlap the connection palm

Tinned copper allows for copper or aluminum conductor connections

Installs quickly and easily

RoHS compliant

SPECIFIKACE

Materiál: Copper

Povrchová úprava: Tinned

Table 1/2

Katalogové číslo	Article Number	A	B	C	D	Thickness (T)
------------------	----------------	---	---	---	---	---------------

FLEXPLATE50	508180	65mm	63mm	45mm	41mm	5mm
FLEXPLATE100	508181	115mm	63mm	45mm	51mm	5mm

Table 2/2


Katalogové číslo	Article Number	Conductor Size	Unit Weight
FLEXPLATE50	508180	220 mm ² , 360 mm ² , 545 mm ² , 640 mm ²	0.16kg
FLEXPLATE100	508181	960 mm ² , 1280 mm ² , 1810 mm ²	0.32kg

DALŠÍ PODROBNOSTI O PRODUKTU

It is mandatory to use the HCBC Clamp associated with the HCBC Plate for proper Flexbus Conductor connection.

It is mandatory to use the PIN associated with the HCBC Plate for proper connection mechanical resistance.

DIAGRAMS

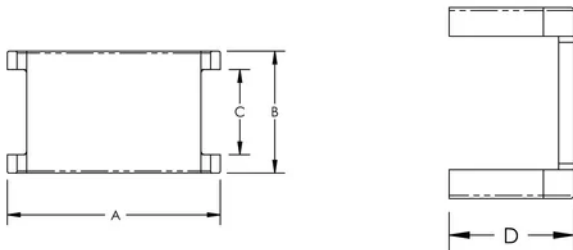

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE