

PEMSA Wire Basket Tray

Data Solutions



The PEMS A Wire Basket Tray is the backbone of PEMS A Wire Basket Tray System. Highly engineered features help ensure a secure installation that complies with industry codes and standards for high-performance cables. Clever design allows the installer to maximize field efficiency with the Rejiband Rapide Integrated Splice.

CERTIFICATIONS



VLASTNOSTI

Provides optimal support for high-performance low voltage and data cables

Innovative Rejiband Rapide installation system

IEC 61537 load rating and earthing compliant

Responsive design and layout services, including seismic

SPECIFIKACE

Table 1/2

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT35X60S4	821003		Stainless Steel 304 (EN 1.4301)		3000mm	35mm
WBT35X60BA	821001	Black	Carbon Steel	Strukturovaný Práškový	3000mm	35mm

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT35X60EG	821000		Carbon Steel	Electrogalvaniz ed	3000mm	35mm
WBT35X100BA	821011	Black	Carbon Steel	Strukturovaný Práškový	3000mm	35mm
WBT35X100EG	821010		Carbon Steel	Electrogalvaniz ed	3000mm	35mm
WBT35X100S4	821013		Stainless Steel 304 (EN 1.4301)		3000mm	35mm
WBT35X150BA	821021	Black	Carbon Steel	Strukturovaný Práškový	3000mm	35mm
WBT35X150EG	821020		Carbon Steel	Electrogalvaniz ed	3000mm	35mm
WBT35X150S4	821023		Stainless Steel 304 (EN 1.4301)		3000mm	35mm
WBT35X200BA	821031	Black	Carbon Steel	Strukturovaný Práškový	3000mm	35mm
WBT35X200EG	821030		Carbon Steel	Electrogalvaniz ed	3000mm	35mm
WBT35X200S4	821033		Stainless Steel 304 (EN 1.4301)		3000mm	35mm
WBT35X300BA	821041	Black	Carbon Steel	Strukturovaný Práškový	3000mm	35mm
WBT35X300EG	821040		Carbon Steel	Electrogalvaniz ed	3000mm	35mm
WBT35X300S4	821043		Stainless Steel 304 (EN 1.4301)		3000mm	35mm
WBT35X400BA	821051	Black	Carbon Steel	Strukturovaný Práškový	3000mm	35mm
WBT35X400EG	821050		Carbon Steel	Electrogalvaniz ed	3000mm	35mm
WBT35X400S4	821053		Stainless Steel 304 (EN 1.4301)		3000mm	35mm
WBT60X60BA	820001	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60mm

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT60X60BG	820002	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60mm
WBT60X60EG	820000		Carbon Steel	Electrogalvaniz ed	3000mm	60mm
WBT60X60S4	820003		Stainless Steel 304 (EN 1.4301)		3000mm	60mm
WBT60X100BA	820011	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60mm
WBT60X100BG	820012	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60mm
WBT60X100EG	820010		Carbon Steel	Electrogalvaniz ed	3000mm	60mm
WBT60X100S4	820013		Stainless Steel 304 (EN 1.4301)		3000mm	60mm
WBT60X150BA	820021	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60mm
WBT60X150BG	820022	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60mm
WBT60X150EG	820020		Carbon Steel	Electrogalvaniz ed	3000mm	60mm
WBT60X150S4	820023		Stainless Steel 304 (EN 1.4301)		3000mm	60mm
WBT60X200BA	820031	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60mm
WBT60X200BG	820032	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60mm
WBT60X200EG	820030		Carbon Steel	Electrogalvaniz ed	3000mm	60mm
WBT60X200S4	820033		Stainless Steel 304 (EN 1.4301)		3000mm	60mm
WBT60X300BA	820041	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60mm
WBT60X300BG	820042	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60mm

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT60X300EG	820040		Carbon Steel	Electrogalvaniz ed	3000mm	60mm
WBT60X300S4	820043		Stainless Steel 304 (EN 1.4301)		3000mm	60mm
WBT60X400BA	820051	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60mm
WBT60X400BG	820052	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60mm
WBT60X400EG	820050		Carbon Steel	Electrogalvaniz ed	3000mm	60mm
WBT60X400S4	820053		Stainless Steel 304 (EN 1.4301)		3000mm	60mm
WBT60X450BA	820081	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60mm
WBT60X450BG	820082	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60mm
WBT60X450EG	820080		Carbon Steel	Electrogalvaniz ed	3000mm	60mm
WBT60X450S4	820083		Stainless Steel 304 (EN 1.4301)		3000mm	60mm
WBT60X500BA	820061	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60mm
WBT60X500BG	820062	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60mm
WBT60X500EG	820060		Carbon Steel	Electrogalvaniz ed	3000mm	60mm
WBT60X500S4	820063		Stainless Steel 304 (EN 1.4301)		3000mm	60mm
WBT60X600BA	820075	Black	Carbon Steel	Strukturovaný Práškový	3000mm	60mm
WBT60X600BG	820076	Black	Carbon Steel	Electrogalvaniz ed	3000mm	60mm
WBT60X600EG	820074		Carbon Steel	Electrogalvaniz ed	3000mm	60mm

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT60X600S4	820077		Stainless Steel 304 (EN 1.4301)		3000mm	60mm
WBT100X100B A	823011	Black	Carbon Steel	Strukturovaný Práškový	3000mm	100mm
WBT100X100B G	823012	Black	Carbon Steel	Electrogalvaniz ed	3000mm	100mm
WBT100X100E G	823010		Carbon Steel	Electrogalvaniz ed	3000mm	100mm
WBT100X100S 4	823013		Stainless Steel 304 (EN 1.4301)		3000mm	100mm
WBT100X150B A	823021	Black	Carbon Steel	Strukturovaný Práškový	3000mm	100mm
WBT100X150B G	823022	Black	Carbon Steel	Electrogalvaniz ed	3000mm	100mm
WBT100X150E G	823020		Carbon Steel	Electrogalvaniz ed	3000mm	100mm
WBT100X150S 4	823023		Stainless Steel 304 (EN 1.4301)		3000mm	100mm
WBT100X200B A	823031	Black	Carbon Steel	Strukturovaný Práškový	3000mm	100mm
WBT100X200B G	823032	Black	Carbon Steel	Electrogalvaniz ed	3000mm	100mm
WBT100X200E G	823030		Carbon Steel	Electrogalvaniz ed	3000mm	100mm
WBT100X200S 4	823033		Stainless Steel 304 (EN 1.4301)		3000mm	100mm

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT100X300B A	823041	Black	Carbon Steel	Strukturovaný Práškový	3000mm	100mm
WBT100X300B G	823042	Black	Carbon Steel	Electrogalvaniz ed	3000mm	100mm
WBT100X300E G	823040		Carbon Steel	Electrogalvaniz ed	3000mm	100mm
WBT100X300S 4	823043		Stainless Steel 304 (EN 1.4301)		3000mm	100mm
WBT100X400B A	823051	Black	Carbon Steel	Strukturovaný Práškový	3000mm	100mm
WBT100X400B G	823052	Black	Carbon Steel	Electrogalvaniz ed	3000mm	100mm
WBT100X400E G	823050		Carbon Steel	Electrogalvaniz ed	3000mm	100mm
WBT100X400S 4	823053		Stainless Steel 304 (EN 1.4301)		3000mm	100mm
WBT100X450B A	823081	Black	Carbon Steel	Strukturovaný Práškový	3000mm	100mm
WBT100X450B G	823082	Black	Carbon Steel	Electrogalvaniz ed	3000mm	100mm
WBT100X450E G	823080		Carbon Steel	Electrogalvaniz ed	3000mm	100mm
WBT100X450S 4	823083		Stainless Steel 304 (EN 1.4301)		3000mm	100mm
WBT100X500B A	823061	Black	Carbon Steel	Strukturovaný Práškový	3000mm	100mm

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT100X500B G	823062	Black	Carbon Steel	Electrogalvaniz ed	3000mm	100mm
WBT100X500E G	823060		Carbon Steel	Electrogalvaniz ed	3000mm	100mm
WBT100X500S 4	823063		Stainless Steel 304 (EN 1.4301)		3000mm	100mm
WBT100X600B A	823071	Black	Carbon Steel	Strukturovaný Práškový	3000mm	100mm
WBT100X600B G	823072	Black	Carbon Steel	Electrogalvaniz ed	3000mm	100mm
WBT100X600E G	823070		Carbon Steel	Electrogalvaniz ed	3000mm	100mm
WBT100X600S 4	823073		Stainless Steel 304 (EN 1.4301)		3000mm	100mm
WBT150X200B A	825031	Black	Carbon Steel	Strukturovaný Práškový	3000mm	150mm
WBT150X200B G	825032	Black	Carbon Steel	Electrogalvaniz ed	3000mm	150mm
WBT150X200E G	825030		Carbon Steel	Electrogalvaniz ed	3000mm	150mm
WBT150X200S 4	825033		Stainless Steel 304 (EN 1.4301)		3000mm	150mm
WBT150X300B A	825041	Black	Carbon Steel	Strukturovaný Práškový	3000mm	150mm
WBT150X300B G	825042	Black	Carbon Steel	Electrogalvaniz ed	3000mm	150mm

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT150X300EG	825040		Carbon Steel	Electrogalvaniz ed	3000mm	150mm
WBT150X300S4	825043		Stainless Steel 304 (EN 1.4301)		3000mm	150mm
WBT150X400BA	825051	Black	Carbon Steel	Strukturovaný Práškový	3000mm	150mm
WBT150X400BG	825052	Black	Carbon Steel	Electrogalvaniz ed	3000mm	150mm
WBT150X400EG	825050		Carbon Steel	Electrogalvaniz ed	3000mm	150mm
WBT150X400S4	825053		Stainless Steel 304 (EN 1.4301)		3000mm	150mm
WBT150X450BA	825081	Black	Carbon Steel	Strukturovaný Práškový	3000mm	150mm
WBT150X450BG	825082	Black	Carbon Steel	Electrogalvaniz ed	3000mm	150mm
WBT150X450EG	825080		Carbon Steel	Electrogalvaniz ed	3000mm	150mm
WBT150X450S4	825083		Stainless Steel 304 (EN 1.4301)		3000mm	150mm
WBT150X500BA	825061	Black	Carbon Steel	Strukturovaný Práškový	3000mm	150mm
WBT150X500BG	825062	Black	Carbon Steel	Electrogalvaniz ed	3000mm	150mm
WBT150X500EG	825060		Carbon Steel	Electrogalvaniz ed	3000mm	150mm

Katalogové číslo	Article Number	Barva	Materiál	Povrchová úprava	Length (L)	Height (H)
WBT150X500S4	825063		Stainless Steel 304 (EN 1.4301)		3000mm	150mm
WBT150X600BA	825071	Black	Carbon Steel	Strukturovaný Práškový	3000mm	150mm
WBT150X600BG	825072	Black	Carbon Steel	Electrogalvaniz ed	3000mm	150mm
WBT150X600EG	825070		Carbon Steel	Electrogalvaniz ed	3000mm	150mm
WBT150X600S4	825073		Stainless Steel 304 (EN 1.4301)		3000mm	150mm
WBT150X900BA	825091	Black	Carbon Steel	Strukturovaný Práškový	3000mm	150mm
WBT150X900BG	825092	Black	Carbon Steel	Electrogalvaniz ed	3000mm	150mm
WBT150X900EG	825090		Carbon Steel	Electrogalvaniz ed	3000mm	150mm
WBT150X900S4	825093		Stainless Steel 304 (EN 1.4301)		3000mm	150mm

Table 2/2

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT35X60S4	821003	60mm	1.19kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X60BA	821001	60mm	1.2kg	
WBT35X60EG	821000	60mm	1.2kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT35X100BA	821011	100mm	1.62kg	

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT35X100EG	821010	100mm	1.62kg	ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT35X100S4	821013	100mm	1.61kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT35X150BA	821021	150mm	1.76kg	
WBT35X150EG	821020	150mm	1.76kg	UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT
WBT35X150S4	821023	150mm	2.12kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT35X200BA	821031	200mm	2.5kg	
WBT35X200EG	821030	200mm	2.5kg	ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT35X200S4	821033	200mm	3.04kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT35X300BA	821041	300mm	3.42kg	
WBT35X300EG	821040	300mm	3.42kg	CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT
WBT35X300S4	821043	300mm	4.13kg	ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT35X400BA	821051	400mm	4.29kg	
WBT35X400EG	821050	400mm	4.29kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT35X400S4	821053	400mm	5.22kg	ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT60X60BA	820001	60mm	2.32kg	
WBT60X60BG	820002	60mm	2.32kg	ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT60X60EG	820000	60mm	2.32kg	ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT60X60S4	820003	60mm	2.32kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT60X100BA	820011	100mm	2.43kg	
WBT60X100BG	820012	100mm	2.43kg	UKCA, CADDY EU WBT, DoP, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT60X100EG	820010	100mm	2.43kg	UKCA, CADDY EU WBT, DoP, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT60X100S4	820013	100mm	2.43kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X150BA	820021	150mm	2.6kg	
WBT60X150BG	820022	150mm	2.6kg	DoP, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT
WBT60X150EG	820020	150mm	2.6kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT60X150S4	820023	150mm	2.6kg	CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT60X200BA	820031	200mm	3.33kg	
WBT60X200BG	820032	200mm	3.33kg	DoP, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT
WBT60X200EG	820030	200mm	3.33kg	CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT60X200S4	820033	200mm	3.33kg	CE, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT
WBT60X300BA	820041	300mm	5.13kg	
WBT60X300BG	820042	300mm	5.13kg	ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT, DoP, CADDY EU WBT
WBT60X300EG	820040	300mm	5.13kg	CE, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT
WBT60X300S4	820043	300mm	5.13kg	CE, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT
WBT60X400BA	820051	400mm	6.21kg	
WBT60X400BG	820052	400mm	6.21kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT60X400EG	820050	400mm	6.21kg	CE, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT
WBT60X400S4	820053	400mm	6.21kg	ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT60X450BA	820081	450mm	6.39kg	
WBT60X450BG	820082	450mm	6.39kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT60X450EG	820080	450mm	6.39kg	CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT60X450S4	820083	450mm	6.39kg	
WBT60X500BA	820061	500mm	7.35kg	
WBT60X500BG	820062	500mm	7.35kg	UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT
WBT60X500EG	820060	500mm	7.35kg	UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT
WBT60X500S4	820063	500mm	7.35kg	UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT
WBT60X600BA	820075	600mm	8.43kg	
WBT60X600BG	820076	600mm	8.43kg	UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT60X600EG	820074	600mm	8.43kg	UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT
WBT60X600S4	820077	600mm	8.43kg	CE, CADDY EU WBT, DoP, CADDY EU WBT, ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT
WBT100X100BA	823011	100mm	3.27kg	
WBT100X100BG	823012	100mm	3.27kg	ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, CE, CADDY EU WBT
WBT100X100EG	823010	100mm	3.27kg	ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, CE, CADDY EU WBT
WBT100X100S4	823013	100mm	3.27kg	CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, DoP, CADDY EU WBT
WBT100X150BA	823021	150mm	3.45kg	
WBT100X150BG	823022	150mm	3.45kg	ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, DoP, CADDY EU WBT, CE, CADDY EU WBT
WBT100X150EG	823020	150mm	3.45kg	UKCA, CADDY EU WBT, DoP, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X150S4	823023	150mm	3.45kg	CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X200BA	823031	200mm	4.14kg	


Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT100X200BG	823032	200mm	4.14kg	DoP, CADDY EU WBT, UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X200EG	823030	200mm	4.14kg	CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X200S4	823033	200mm	4.14kg	CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X300BA	823041	300mm	6.15kg	
WBT100X300BG	823042	300mm	6.15kg	DoP, CADDY EU WBT, UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X300EG	823040	300mm	6.15kg	CE, CADDY EU WBT, ANOR EU WTB EG S4 BG, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT100X300S4	823043	300mm	6.15kg	CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X400BA	823051	400mm	7.23kg	
WBT100X400BG	823052	400mm	7.23kg	UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT
WBT100X400EG	823050	400mm	7.23kg	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT100X400S4	823053	400mm	7.23kg	DoP, CADDY EU WBT, CE, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X450BA	823081	450mm	7.44kg	
WBT100X450BG	823082	450mm	7.44kg	UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG, CE, CADDY EU WBT
WBT100X450EG	823080	450mm	7.44kg	CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X450S4	823083	450mm	7.44kg	
WBT100X500BA	823061	500mm	8.34kg	
WBT100X500BG	823062	500mm	8.34kg	ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT100X500EG	823060	500mm	8.34kg	ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT100X500S4	823063	500mm	8.34kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT100X600BA	823071	600mm	9.42kg	
WBT100X600BG	823072	600mm	9.42kg	ANOR EU WTB EG S4 BG, UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT100X600EG	823070	600mm	9.42kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT100X600S4	823073	600mm	9.42kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT, ANOR EU WTB EG S4 BG
WBT150X200BA	825031	200mm	6.01kg	
WBT150X200BG	825032	200mm	6.01kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT150X200EG	825030	200mm	6.01kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT, DoP, CADDY EU WBT
WBT150X200S4	825033	200mm	6.01kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X300BA	825041	300mm	7.29kg	
WBT150X300BG	825042	300mm	7.29kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT150X300EG	825040	300mm	7.29kg	CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X300S4	825043	300mm	7.29kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT150X400BA	825051	400mm	8.47kg	
WBT150X400BG	825052	400mm	8.47kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT150X400EG	825050	400mm	8.47kg	CE, CADDY EU WBT, DoP, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X400S4	825053	400mm	8.47kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT150X450BA	825081	450mm	8.68kg	
WBT150X450BG	825082	450mm	8.68kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X450EG	825080	450mm	8.68kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT150X450S4	825083	450mm	8.68kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT

Katalogové číslo	Article Number	Width (W)	Unit Weight	Certifications
WBT150X500BA	825061	500mm	9.7kg	
WBT150X500BG	825062	500mm	9.7kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X500EG	825060	500mm	9.7kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT150X500S4	825063	500mm	9.7kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X600BA	825071	600mm	10.65kg	
WBT150X600BG	825072	600mm	10.65kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT150X600EG	825070	600mm	10.65kg	UKCA, CADDY EU WBT, CE, CADDY EU WBT
WBT150X600S4	825073	600mm	10.65kg	CE, CADDY EU WBT, UKCA, CADDY EU WBT
WBT150X900BA	825091	900mm	15.98kg	
WBT150X900BG	825092	900mm	15.98kg	
WBT150X900EG	825090	900mm	15.98kg	
WBT150X900S4	825093	900mm	15.98kg	

DIAGRAMS

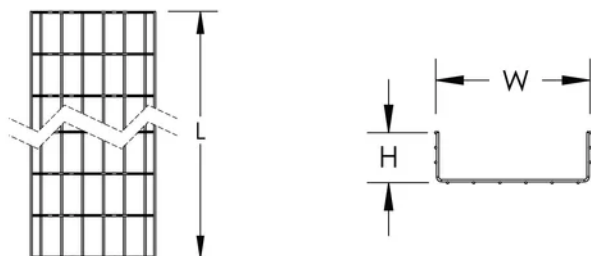

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit

selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE