


# Socket Strip, UTE

## Data Solutions

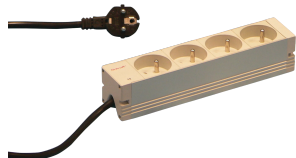

Modular, compact PDU with many function elements. Using a 1 U by 1 U aluminum chassis the PDU can easily be integrated in a rack with UTE outlets.

### CERTIFICATIONS



### VLASTNOSTI

230 V, 16 A

In accordance with NFC 61-303

Socket strip with UTE sockets

Mounting height 1 U

Horizontal or vertical mounting

Connecting cable 2 m, with SCHUKO/UTE plug

Socket strips can be rotated through all four directions (in 90° increments) during installation

### SPECIFIKACE

|                      |                   |
|----------------------|-------------------|
| <b>Materiál:</b>     | Hliník; Polyamide |
| <b>Barva:</b>        | Grey              |
| <b>Product Type:</b> | Socket Strip      |

Table 1/2

| Katalogové číslo | Typ zásuvky | Socket Quantity | Switched Outlets | Napětí střídavé | Function                                         | Množství v balení |
|------------------|-------------|-----------------|------------------|-----------------|--------------------------------------------------|-------------------|
| 60110-220        | UTE         | 4               | No               | 230V            |                                                  | 1                 |
| 60110-221        | UTE         | 9               | No               | 230V            |                                                  | 1                 |
| 60110-225        | UTE         | 8               | Yes              | 230V            |                                                  | 1                 |
| 60110-267        | UTE         | 6               | No               | 230V            | Transient Protection, Mains Suppression Filter   | 1                 |
| 60110-227        | UTE         | 8               | No               | 230V            | Transient Protection                             | 1                 |
| 60110-229        | UTE         | 7               | No               | 230V            | Mains Suppression Filter                         | 1                 |
| 60110-222        | UTE         | 12              | No               | 230V            |                                                  | 1                 |
| 60110-223        | UTE         | 15              | No               | 230V            |                                                  | 1                 |
| 60110-224        | UTE         | 19              | No               | 230V            |                                                  | 1                 |
| 60110-226        | UTE         | 12              | Yes              | 230V            |                                                  | 1                 |
| 60110-228        | UTE         | 6               | No               | 230V            | Overcurrent Protection                           | 1                 |
| 60110-230        | UTE         | 6               | No               | 230V            | Fault Current Protection                         | 1                 |
| 60110-231        | UTE         | 6               | No               | 230V            | Fault Current Protection, Overcurrent Protection | 1                 |

Table 2/2

| Katalogové číslo | Hloubka | Povrchová úprava | Length  |
|------------------|---------|------------------|---------|
| 60110-220        | 44mm    | Anodized         | 210mm   |
| 60110-221        | 44mm    | Anodized         | 438.5mm |

| Katalogové číslo | Hloubka | Povrchová úprava | Length  |
|------------------|---------|------------------|---------|
| 60110-225        | 44mm    | Anodized         | 438.5mm |
| 60110-267        | 44mm    | Anodized         | 438.5mm |
| 60110-227        | 44mm    | Anodized         | 438.5mm |
| 60110-229        | 44mm    | Anodized         | 438.5mm |
| 60110-222        | 44mm    | Anodized         | 947.5mm |
| 60110-223        | 44mm    | Anodized         | 1202mm  |
| 60110-224        | 44mm    | Anodized         | 1753mm  |
| 60110-226        | 44mm    | Anodized         | 947.5mm |
| 60110-228        | 75mm    | Anodized         | 438.5mm |
| 60110-230        | 88mm    | Anodized         | 438.5mm |
| 60110-231        | 88mm    | Anodized         | 438.5mm |

## DALŠÍ PODROBNOSTI O PRODUKTU

Please order bracket for vertical mounting separately.

## UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na [www.nvent.com](http://www.nvent.com) a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**