

Telecom Main Grounding Busbar

Data Solutions



CERTIFICATIONS



VLASTNOSTI

Meets TIA-607-C and TIA-607-D and conforms to BICSI® recommendations

Complies with NEMA® standards

Accepts two hole lugs with 5/16" or 7/16" bolt holes (hardware not included)

Telecom grounding busbar splice kits are available to extend the length of the busbar

SPECIFIKACE

Thickness (T): 6.35mm
Width (W): 101.6mm
Materiál: Copper

Table 1/2


Katalogové číslo	Tin Plating	Length 1 (L1)	Length 2 (L2)	Hole Size 1 Number of Pairs	Hole Size 2 Number of Pairs	A
------------------	-------------	---------------	---------------	--------------------------------	--------------------------------	---

TMGBA12L15P	No	305mm	229mm	15	3	25.4mm
TMGBA12L15PT	Yes	305mm	229mm	15	3	25.4mm
TMGBA20L27P	No	508mm	229mm	27	3	25.4mm
TMGBA24L33PT	Yes	610mm	457mm	33	5	25.4mm

Table 2/2

Katalogové číslo	B	C	D
TMGBA12L15P	28.6mm	15.9mm	15.9mm
TMGBA12L15PT	28.6mm	15.9mm	15.9mm
TMGBA20L27P	28.6mm	15.9mm	15.9mm
TMGBA24L33PT	28.6mm	15.9mm	15.9mm

DIAGRAMS

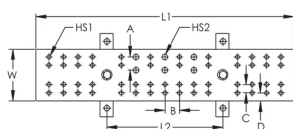

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE