


TR Four Pole Distribution Block, 125 A

Data Solutions

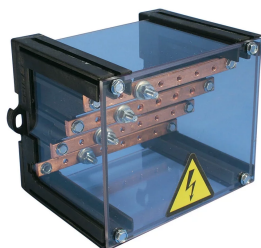

CERTIFICATIONS



VLASTNOSTI

Easily clips onto DIN rail or mounts to panel with screws

Equipped with a current input plug

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

SPECIFIKACE

Katalogové číslo	TR-125A
Article Number	563150


Katalogové číslo	TR-125A
Materiál	Copper Glass Fibre Reinforced Polyamide Plexiglass
Max Working Voltage, IEC (Ui)	1000
Peak Short Circuit Current (Ipk)	40kA
Short Term Withstand Current (Icw) 1s	8.4kA
Line Side Number of Connections	1
Load Side Number of Connections	5
Thread Size 1 (TS1)	M5
Thread Size 2 (TS2)	M6
Hloubka (D)	117mm
Height (H)	126mm
Width (W)	150mm
Unit Weight	0.68kg
Flammability Rating	UL® 94V-0
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)

DALŠÍ PODROBNOSTI O PRODUKTU

Thread Size 2 represents input plug.

Line side and load side number of connections are per pole.

DIAGRAMS

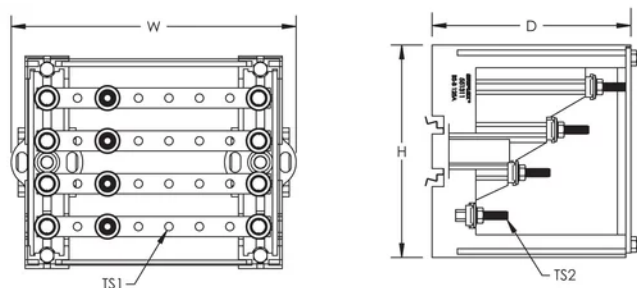

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit

selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE