


TR Four Pole Distribution Block, 400 A

Data Solutions

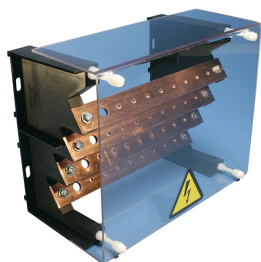

CERTIFICATIONS



VLASTNOSTI

Easily fixes onto DIN rail or mounts with screws

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

SPECIFIKACE


Katalogové číslo	TR-400A
Article Number	562010
Materiál	Copper Glass Fibre Reinforced Polyamide Plexiglass

Katalogové číslo	TR-400A
Max Working Voltage, IEC (Ui)	1000
Peak Short Circuit Current (Ipk)	34kA
Short Term Withstand Current (Icw) 1s	28kA
Line Side Number of Connections	1
Load Side Number of Connections	8
Hole Size (HS)	10mm
Thread Size (TS)	M6
Hloubka (D)	140mm
Height (H)	240mm
Width (W)	300mm
Unit Weight	2.83kg
Flammability Rating	UL® 94V-0
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)

DALŠÍ PODROBNOSTI O PRODUKTU

Line side and load side number of connections are per pole.

DIAGRAMS

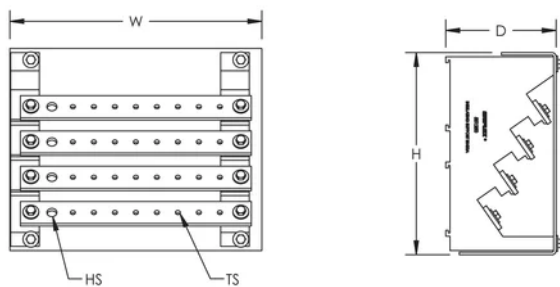

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE