

TRC Four Pole Distribution Block, 400 A

Data Solutions



CERTIFICATIONS



VLASTNOSTI

Transparent protection cover

Bolts included for output connections

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

SPECIFIKACE

Katalogové číslo	TRC-400A
Article Number	563180
Materiál	Copper Glass Fibre Reinforced Polyamide Plexiglass
Max Working Voltage, IEC (Ui)	1000


Katalogové číslo	TRC-400A
Peak Short Circuit Current (I _{pk})	118kA
Short Term Withstand Current (I _{cw}) 1s	28kA
Line Side Number of Connections	1
Load Side Number of Connections	10
Thread Size 1 (TS1)	M6
Thread Size 2 (TS2)	M10
Hloubka (D)	50mm
Height (H)	338 – 390mm
Width (W)	260mm
A	290mm
Unit Weight	2.65kg
Flammability Rating	UL® 94V-0
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)

DALŠÍ PODROBNOSTI O PRODUKTU

Thread Size 2 represents input plug.

Line side and load side number of connections are per pole.

DIAGRAMS

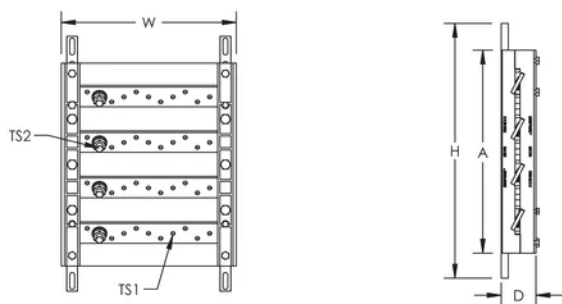

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE