


TRS Four Pole Distribution Block, 160 A

Data Solutions

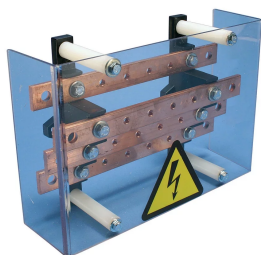

CERTIFICATIONS



VLASTNOSTI

Easily fixes onto asymmetric DIN rail or mounts with screws

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

SPECIFIKACE


Katalogové číslo	TRS-160A
Article Number	563160
Materiál	Copper Glass Fibre Reinforced Polyamide Plexiglass

Katalogové číslo	TRS-160A
Max Working Voltage, IEC (Ui)	630
Peak Short Circuit Current (Ipk)	34kA
Short Term Withstand Current (Icw) 1s	13.2kA
Line Side Number of Connections	2
Load Side Number of Connections	4
Hole Size (HS)	8mm
Thread Size (TS)	M6
Hloubka (D)	68mm
Height (H)	150mm
Width (W)	230mm
Unit Weight	1.15kg
Flammability Rating	UL® 94V-0
Complies With	IEC® 60439.1 IEC® 61439.1 IEC® 60695-2-11 (Glow Wire Test 960 °C)

DALŠÍ PODROBNOSTI O PRODUKTU

Line side and load side number of connections are per pole.

DIAGRAMS

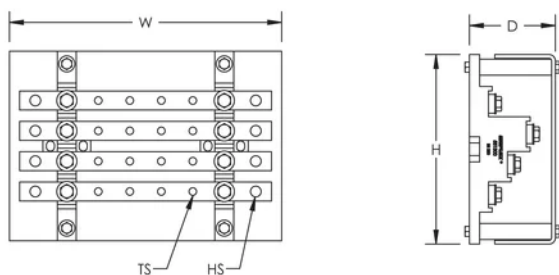

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE