


Air Terminal Base, Horizontal Mount, Imperial Thread



CERTIFICATIONS

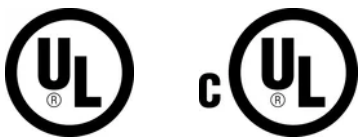

VLASTNOSTI

Can be fastened mechanically or bonded using hot pitch, roofing compound or commercial adhesive on built-up roof surfaces or other location where holes cannot be made

Positive single bolt tension for multi-directional cable clamping

SPECIFIKACE

Conductor Size, UL: Class 1 - Class 2 (4/0 Max)


Table 1/2

Katalogové číslo	Materiál	Thread Size (TS)	Hole Size (HS)	Hloubka (D)	Height (H)	Width (W)
LPA30912	Hliník	1/2" UNC	7.94 mm	101.6mm	20.64 mm	101.6 mm
LPC30958	Copper	5/8" UNC	7.94 mm	101.6mm	20.64 mm	101.6 mm

Table 2/2

Katalogové číslo	Unit Weight
LPA30912	0.14 kg
LPC30958	0.44 kg

DIAGRAMS

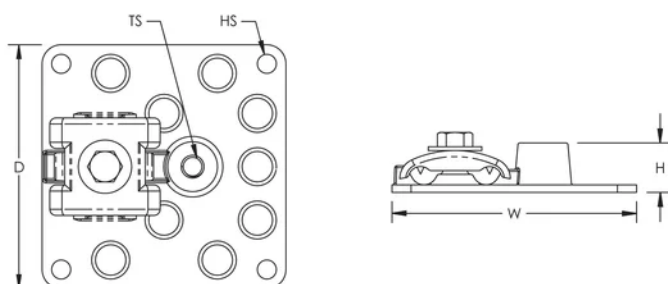

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE