



Air Terminal Base, Imperial Thread

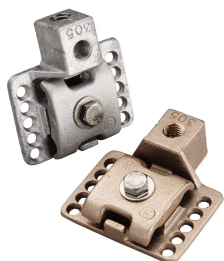

CERTIFICATIONS

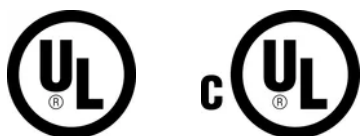

VLASTNOSTI

Install with adhesive or screw down fixings

Mechanical connection recommended for vertical installation

Positive single bolt tension for multi-directional cable clamping

SPECIFIKACE

Povrchová úprava:	Bare
Conductor Size, UL:	Class 1 - Class 2 (4/0 Max)
Materiál:	Copper


Table 1/2

Katalogové číslo	Thread Size (TS)	Mounting	Hole Size (HS)	Hloubka (D)	Height (H)	Width (W)
LPC30558V	5/8" UNC	Vertical	6.35 mm	73.7mm	25.4 mm	77.9 mm
LPC30558H	5/8" UNC	Horizontal	6.35 mm	73.7mm	25.4 mm	77.9 mm

Table 2/2

Katalogové číslo	Unit Weight
LPC30558V	0.38 kg
LPC30558H	0.38 kg

DIAGRAMS

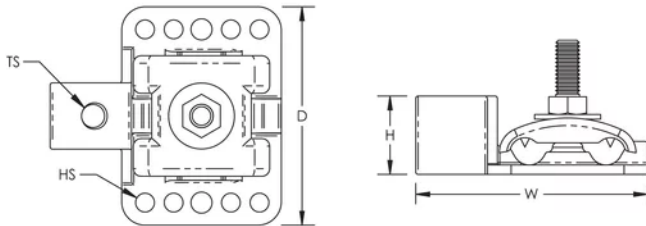

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE