



Air Terminal Base, Stamped Adjustable, Imperial Thread

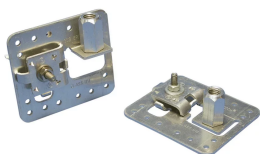

CERTIFICATIONS

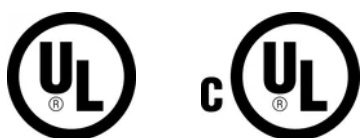

VLASTNOSTI

For use on flat, vertical or sloping surfaces

Air terminal support tab is field adjustable, eliminating the need for swivel adaptors

Available pre-configured for vertical applications

Install with adhesive or screw down fixings

Positive single bolt tension for multi-directional cable clamping

SPECIFIKACE

Conductor Size, UL: Class 1 - Class 2 (4/0 Max)

Table 1/2

Katalogové číslo	Materiál	Thread Size (TS)	Typ	Hole Size (HS)	Hloubka (D)	Height (H)
LPC30258	Bronze, Brass	5/8" UNC	Flat	7.14 mm	88.9mm	34.92 mm

Katalogové číslo	Materiál	Thread Size (TS)	Typ	Hole Size (HS)	Hloubka (D)	Height (H)
LPC302M16	Bronze, Brass	M16	Flat	7.14 mm	88.9mm	34.92 mm
LPA30258	Hliník	5/8" UNC	Flat	7.14 mm	88.9mm	34.92 mm
LPC30212	Bronze, Brass	1/2" UNC	Flat	7.14 mm	88.9mm	34.92 mm
LPA30212	Hliník	1/2" UNC	Flat	7.14 mm	88.9mm	34.92 mm


Table 2/2

Katalogové číslo	Width (W)
LPC30258	101.6 mm
LPC302M16	101.6 mm
LPA30258	101.6 mm
LPC30212	101.6 mm
LPA30212	101.6 mm

DALŠÍ PODROBNOSTI O PRODUKTU

Vertical type bases are factory pre-configured for vertical mount applications.

DIAGRAMS

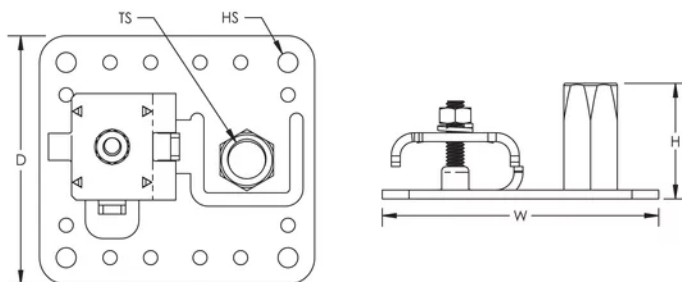

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRachte