

B161/B164 Earthpoint, Four Stud



VLASTNOSTI

Long-lasting design

Low ground resistance and impedance

Superior electrical conductivity and resistance to corrosion

Electrically and mechanically robust and reliable

Easy to install as a Prefabricated Earthbridge once nVent ERICO Cadweld welded to a piece of conductor

SPECIFIKACE

Materiál: Copper

Table 1/2

Katalogové číslo	Article Number	Width 1 (W1)	Width 2 (W2)	Depth 1 (D1)	Depth 2 (D2)	Height (H)
B16412A	166060	44.5 mm	85 mm	44.5mm	85mm	70 mm
B16110B	166030	30 mm	65 mm	30mm	65mm	42 mm

Table 2/2


Katalogové číslo	Article Number	Diameter (Ø)	Thread Size (TS)
B16412A	166060	10.7 mm	M12

Katalogové číslo	Article Number	Diameter (Ø)	Thread Size (TS)
B16110B	166030	14 mm	M10

DALŠÍ PODROBNOSTI O PRODUKTU

Assemblies require conductors and nVent ERICO Cadweld connections, which must be ordered separately.

DIAGRAMS

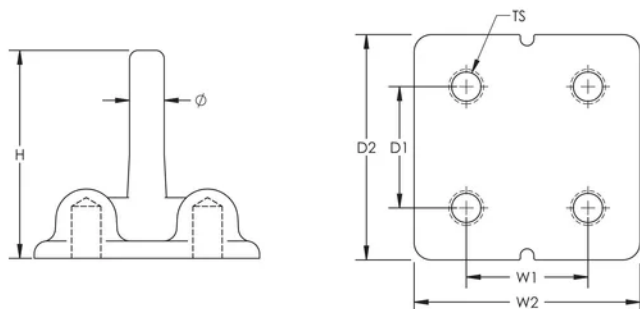

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE