


Cable to Web of Rail Mold Pair, Power

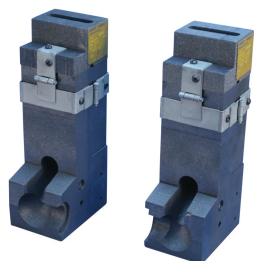

VLASTNOSTI

Replacement mold pair designed for the installation of track circuits and jumper bonds to the neutral axis

Sold in pairs

SPECIFIKACE

Materiál: Graphite

Bond Terminal Style: W

Table 1/1

Katalogové číslo	Rail Type	Conductor Size	Conductor Outer Diameter, Nominal	Welder Style
PBWX201	85 lb to 141 lb T-Rail Sections	35 mm ² Ropelay	7.75mm	T20
PBWY301	UIC60	50 mm ² Concentric	8.89mm	T20
PBWX3	85 lb to 141 lb T-Rail Sections	50 mm ² Ropelay	9.13mm	T20
PBW2C	85 lb to 141 lb T-Rail Sections	1/0 Concentric	9.47mm	T20
PBW2G	85 lb to 141 lb T-Rail Sections	2/0 Concentric	10.62mm	T20
PBW2E	85 lb to 141 lb T-Rail Sections	1/0 Ropelay	10.87mm	T20

Katalogové číslo	Rail Type	Conductor Size	Conductor Outer Diameter, Nominal	Welder Style
PBW2J	85 lb to 141 lb T-Rail Sections	2/0 Ropelay	12.19mm	T20
PBWX5	85 lb to 141 lb T-Rail Sections	95 mm ² Ropelay	12.83mm	T20
PBW2Q	85 lb to 141 lb T-Rail Sections	4/0 Concentric	13.41mm	T20
PBW9F	85 lb to 141 lb T-Rail Sections	19/#9 Copperweld	14.53mm	T20
PBW2S	85 lb to 141 lb T-Rail Sections	4/0 Ropelay	15.49mm	T20
PBXLWX5	85 lb to 141 lb T-Rail Sections	95 mm ² Ropelay	15.52mm	T20
PBWX7	85 lb to 141 lb T-Rail Sections	150 mm ² Ropelay	16mm	T20
PBWS7	85 lb to 141 lb T-Rail Sections	4/0 Composite	16.66mm	T20
PBW3D	85 lb to 141 lb T-Rail Sections	350 kcmil Concentric	17.3mm	T20
PBWX8	85 lb to 141 lb T-Rail Sections	185 mm ² Ropelay	17.8mm	T20
PBW2W	85 lb to 141 lb T-Rail Sections	250 kcmil Ropelay	19.05mm	T20
PBW2W135	135 lb Bethlehem	250 kcmil Ropelay	19.05mm	T20
PBW2W20AS	20 lb ASCE	250 kcmil Ropelay	19.05mm	T20
PBW2W40AS	40 lb ASCE	250 kcmil Ropelay	19.05mm	T20
PBW3B	85 lb to 141 lb T-Rail Sections	300 kcmil Ropelay	20.32mm	T20
PBW3S	85 lb to 141 lb T-Rail Sections	500 kcmil Ropelay	26.42mm	T20
PBW3SZU160	ZU160 Rail	500 kcmil Ropelay	26.42mm	T20

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE