


Cable to Web of Rail Replacement Mold Pair, Signal

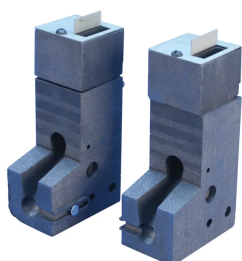

VLASTNOSTI

Replacement mold pair designed for the installation of track circuits and jumper bonds to the neutral axis

Sold in pairs

SPECIFIKACE

Materiál: Graphite

Table 1/1

Katalogové číslo	Rail Type	Bond Terminal Style	Conductor Size	Conductor Outer Diameter, Nominal	Welder Style	Bond Clips Included
SBB200R	85 lb to 141 lb T-Rail Sections	1" Tab	10 mm ² Stranded	4.12mm	TB5, T21	No
SBB200A	85 lb to 141 lb T-Rail Sections	3/4" XS	3/16" Bondstrand	4.76mm	TB5, T21	Yes
SBB200B	85 lb to 141 lb T-Rail Sections	3/4" Tab	3/16" Bondstrand	4.76mm	TB5, T21	Yes
SBB200C	85 lb to 141 lb T-Rail Sections	1" Tab	3/16" Bondstrand	4.76mm	TB5, T21	Yes
SBB200C12AS	12 lb ASCE	1" Tab	3/16" Bondstrand	4.76mm	T21, TB5	No

Katalogové číslo	Rail Type	Bond Terminal Style	Conductor Size	Conductor OuterDiameter, Nominal	Welder Style	Bond Clips Included
SBB200D	85 lb to 141 lb T-Rail Sections	1 1/2" Tab	3/16" Bondstrand	4.76mm	T21, TB5	No
SBB200G	85 lb to 141 lb T-Rail Sections	1" Tab	3/16" Bondstrand	4.76mm	T21, TB5	No
SBB200U	RI60	1" Tab	3/16" Bondstrand	4.76mm	TB5, T21	No
SBB200Y	85 lb to 141 lb T-Rail Sections	1" Tab	16 mm ² Concentric	5.18mm	T21, TB5	No
SBB200L	85 lb to 141 lb T-Rail Sections	1" Tab	22 mm ² Ropelay	6.1mm	T21, TB5	No
SBB200X	85 lb to 141 lb T-Rail Sections	1" Tab	25 mm ² Stranded	6.6mm	TB5, T21	No
SBB200P	85 lb to 141 lb T-Rail Sections	1" Tab	35 mm ² Concentric	7.75mm	T21, TB5	Not Required
SBB200E	85 lb to 141 lb T-Rail Sections	1" Tab	5/16" Bondstrand	7.94mm	TB5, T21	Yes

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE