


Cast U-Bolt Pipe Clamp

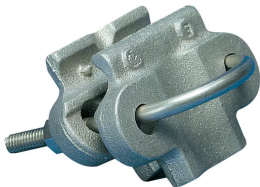

CERTIFICATIONS



VLASTNOSTI

Clamp for bonding conductor to handrails, pipes and rebar to lightning protection system

Listed to UL® 96

SPECIFIKACE


Table 1/2

Katalogové číslo	Conductor Size, UL	Materiál	Povrchová úprava	Outer Diameter (OD)	Hloubka (D)	Height (H)
LPC570	Class 1 - Class 2 (4/0 Max), Secondary	Brass	Bare	17.3 - 38.1 mm	45.72mm	76.2 mm

Table 2/2

Katalogové číslo	Width (W)	Unit Weight
LPC570	67.82 mm	0.32 kg

DIAGRAMS

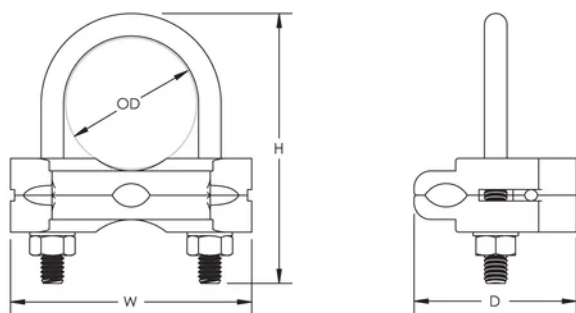

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE