

Compression Coupler for Copper-Bonded Ground Rod, Pointed



CERTIFICATIONS



VLASTNOSTI

Threadless compression coupler for use with pointed copper-bonded ground rods

Inside of coupler is tapered so ground rod compresses during installation to form an irreversible conductive connection

SPECIFIKACE

Table 1/2						
Katalogové číslo	Article Number	Materiál	Ground Rod Diameter, Nominal	Length (L)	Unit Weight	Complies With
BR12	156650	Brass	1/2"	70mm	0.13 kg	
CC12F	158000	Silicon Bronze	1/2"	69.8mm	0.13 kg	
CC58	158010	Silicon Bronze	5/8"	69.8mm	0.15 kg	IEC® EN 62561-2

Katalogové číslo	Article Number	Materiál	Ground Rod Diameter, Nominal	Length (L)	Unit Weight	Complies With
CC34	158020	Silicon Bronze	3/4"	69.8mm	0.2 kg	IEC® EN 62561-2


Table 2/2

Katalogové číslo	Article Number	Certifications
BR12	156650	
CC12F	158000	UL, CSA-US, cUL, CSA
CC58	158010	UL, CSA, cUL, CSA-US, RUS
CC34	158020	CSA, UL, cUL, CSA-US

DALŠÍ PODROBNOSTI O PRODUKTU

IEC® EN 62561-2 supercedes EN 50164-2.

DIAGRAMS

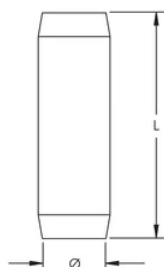

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE