

Drill Distance Gauge, Two Plates



VLASTNOSTI

Used for making precise drill hole spacings of ± 1 mm (0.039")

Common applications include axle counters and wheel sensors

SPECIFIKACE


Materiál: Ocel

Table 1/2

Katalogové číslo	Article Number	Drill Guide Included	Rail Type	Length 1 (L1)	Length 2 (L2)	Width (W)
DDGTIEFEB145	716534	Yes	S49, S54, UIC60	339.1 mm	145 mm	87.9 mm
DDG635119	715263	No	B95	319 mm		87.9 mm

Table 2/2

Katalogové číslo	Article Number	Height 1 (H1)	Height 2 (H2)	Hole Size (HS)	A
DDGTIEFEB145	716534	50mm	30mm	13.5 mm	145 mm
DDG635119	715263	50mm			119 mm

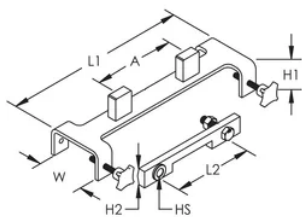

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE