


Joint Bond T6 Complete Welder Pair, Signal, 1" Tab Bond Terminal Style, 3/16" Bondstrand

KATALOGOVÉ ČÍSLO

SBTBT6D

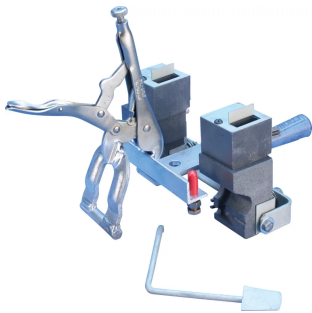

VLASTNOSTI

Complete welder assembly provides a convenient means of attaching jumper bonds to the head of the rail, across the joint

Connection is made within the confines of the splice bar

Includes mold cleaner

VLASTNOSTI PRODUKTU

Article Number: 715408

Materiál: Ocel;Graphite;Thermoplastic

Rail Type: 85 lb to 141 lb T-Rail Sections

Bond Terminal Style: 1" Tab

Conductor Size: 3/16" Bondstrand

Conductor Outer Diameter, Nominal: 4.76mm

Bond Length: 247.7mm

Welder Style: T6

Mold Only: No

Replacement Mold: SBS5838

Welding Material: SB25 x 2, Sold Separately

Frame: SBS5838F, Sold Separately

Bond Clip: SBS2659 x 2, Sold Separately

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE