


Ground Rod Clamp



CERTIFICATIONS

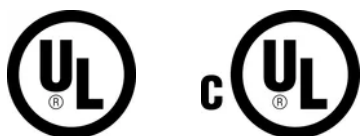

VLASTNOSTI

Unique stamped body design will not crack as mechanical forces are increased

Stainless steel threads will not strip if over-tightened

Unique internal profile offers pull-out load in excess of four times the UL® 96 requirement

Listed to UL® 96

SPECIFIKACE


Table 1/2

Katalogové číslo	Materiál	Conductor Size, UL	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Height (H)	Length (L)
LPC790	Copper	Class 1 - Class 2 (4/0 Max)	1/2" - 3/4"	12.7 - 17.3 mm	42 mm	44.5mm

Table 2/2

Katalogové číslo	Width (W)	Unit Weight
LPC790	23.8 mm	0.15 kg

DIAGRAMS

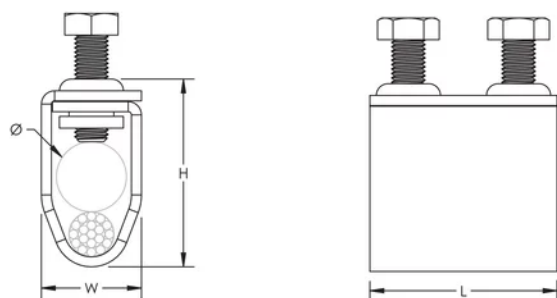

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE