

Ground Rod Clamp with Prefabricated Pigtail



VLASTNOSTI

Prefabricated assembly including grounding clamp with pigtail

Fast and simple installation requires only a hammer


SPECIFIKACE

Material: Copper

Insulation: Green and Yellow Insulated Cable

Table 1/1

Katalogové číslo	Article Number	Ground Rod Diameter, Nominal	Length (L)	Pigtail Length	Conductor Size	Unit Weight
EPT1225300	158610	1/2"	70mm	300mm	25 mm ² Stranded	0.5 kg
EPT1450350	158290	5/8"	75mm	350mm	50 mm ² Stranded	0.5 kg
EPT1425350	158675	5/8"	75mm	350mm	25 mm ² Stranded	0.5 kg

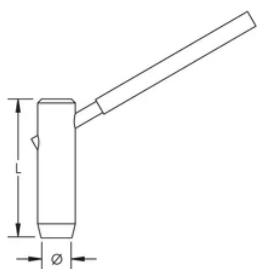

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRachte