


Ground Rod Clamp, Rod to Conductor, Stainless Steel



CERTIFICATIONS

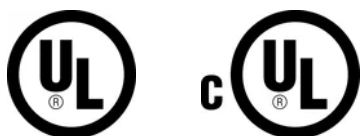

VLASTNOSTI

Unique stamped body design will not crack from excessive torque

Provides a greater surface area contact to allow improved performance of the connector

Compatible with copper, copper bonded, galvanized, stainless steel, rebar and plain steel ground rods and electrodes

SPECIFIKACE


Table 1/2

Katalogové číslo	Article Number	Materiál	Torque (TQ)	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Conductor Size
SP58	158185	Stainless Steel 304 (EN 1.4301)	16.90 - 33.9 N·m	1/2" - 5/8"	12.7 - 15.9 mm	#10 Stranded - #2 Stranded, 6 mm² Stranded - 25 mm² Stranded

Table 2/2

Katalogové číslo	Article Number	Wrench Size
SP58	158185	1/2"

DIAGRAMS

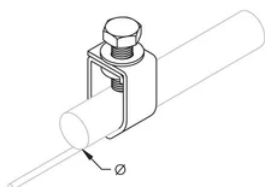

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE