

Ground Rod Driver



VLASTNOSTI

Usable on all types of round ground rods: copper-bonded, galvanized, and stainless steel


Inserts are interchangeable with standard ground rod driver body

The driver will not deform the end of the rod, making connection of the ground conductor quick and easy

SPECIFIKACE

Table 1/1

Katalogové číslo	Article Number	Ground Rod Diameter, Nominal	Ground Rod Diameter, Actual (Ø)	Length (L)	Unit Weight
EGRD34	158520	3/4" Max	17.2 mm Max	1500mm	10.4 kg
EGRD58	158500	5/8" Max	14.2 mm Max	1500mm	10.4 kg

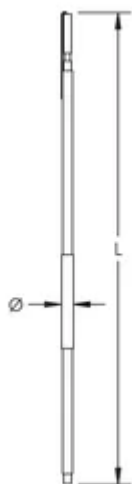

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE