


Joint Bond Mold Pair with Mounting Parts and Clips, Signal

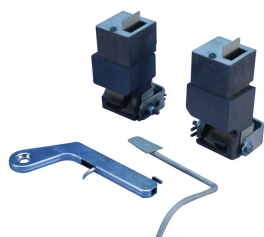

VLASTNOSTI

Pair of replacement molds with mounting parts designed for the installation of jumper bonds to the head of the rail

Connection is made within the confines of the splice bar

Includes mold cleaner and flint ignitor

SPECIFIKACE

Rail Type: 85 lb to 141 lb T-Rail Sections

Product: Mold, frames, and clips

Table 1/1

Katalogové číslo	Article Number	Materiál	Bond Terminal Style	Conductor Size	Conductor Outer Diameter, Nominal	Welder Style
SBM456F		Ocel, Graphite	3/4" XS	3/16" Bondstrand	4.76mm	T6, T7
SBS925F		Ocel, Graphite	Head Free	3/16" Bondstrand	4.76mm	T6, T7
SBS5838F	165171	Ocel, Graphite	3/4" Tab	3/16" Bondstrand	4.76mm	T6, T7
SBS898F		Ocel, Graphite	1" Tab	5/16" Bondstrand	7.94mm	T6, T7

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRachte