


Joint Bond Mold Pair Only, Signal

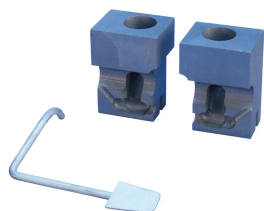

VLASTNOSTI

Pair of replacement molds designed for the installation of jumper bonds to the head of the rail

Connection is made within the confines of the splice plate

SPECIFIKACE

Materiál: Graphite

Table 1/1

Katalogové číslo	Rail Type	Bond Terminal Style	Product	Conductor Size	Conductor Outer Diameter, Nominal	Welder Style
SBM456	85 lb to 141 lb T-Rail Sections	3/4" XS	Mold and Mold Cleaning Tool	3/16" Bondstrand	4.76mm	T6, T7
SBM456M	85 lb to 141 lb T-Rail Sections	3/4" XS	Mold only	3/16" Bondstrand	4.76mm	T6, T7
SBS5838	85 lb to 141 lb T-Rail Sections	3/4" Tab	Mold and Mold Cleaning Tool	3/16" Bondstrand	4.76mm	T6, T7
SBS5838M	85 lb to 141 lb T-Rail Sections	3/4" Tab	Mold only	3/16" Bondstrand	4.76mm	T6, T7
SBS5839	85 lb to 141 lb T-Rail Sections	1" Tab	Mold and Mold Cleaning Tool	3/16" Bondstrand	4.76mm	T6, T7
SBS5839M	85 lb to 141 lb T-Rail Sections	1" Tab	Mold only	3/16" Bondstrand	4.76mm	T7

Katalogové číslo	Rail Type	Bond Terminal Style	Product	Conductor Size	Conductor OuterDiameter, Nominal	Welder Style
SBS925	Head-Free Rail	Head Free	Mold and Mold Cleaning Tool	3/16" Bondstrand	4.76mm	T6, T7
SBS925M	Head-Free Rail	Head Free	Mold only	3/16" Bondstrand	4.76mm	T6, T7
SBB492	Head-Free Rail	Head Free	Mold and Mold Cleaning Tool	5/16" Bondstrand	7.94mm	T6, T7
SBB492M	Head-Free Rail	Head Free	Mold only	5/16" Bondstrand	7.94mm	T6, T7
SBS898	85 lb to 141 lb T-Rail Sections	1" Tab	Mold and Mold Cleaning Tool	5/16" Bondstrand	7.94mm	T6, T7
SBS898M	85 lb to 141 lb T-Rail Sections	1" Tab	Mold only	5/16" Bondstrand	7.94mm	T6, T7
SBTBT71YM	85 lb to 141 lb T-Rail Sections	1" Tab	Mold only	#1 Concentric	8.43mm	T7

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including silica, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE