


Joint Bond T6 Mold Welder Frame Assembly, Signal

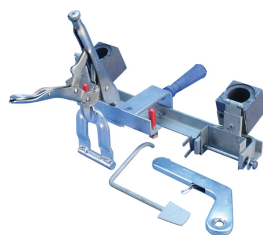

VLASTNOSTI

Replacement welder frame assembly for T6 joint bond welders

Includes frame with mold lid, mold handle, mold cleaner and flint ignitor

SPECIFIKACE

Rail Type: 85 lb to 141 lb T-Rail Sections

Table 1/1

Katalogové číslo	Article Number	Materiál	Bond Terminal Style	Conductor Size	Conductor Outer Diameter, Nominal	Welder Style
SBXST6AX		Graphite, Steel, Thermoplastic	XS	3/16" Bondstrand	4.76mm	T6
SBXST6CX		Graphite, Steel, Thermoplastic	XS	3/16" Bondstrand	4.76mm	T6
SBXT6CE	161120	Graphite, Steel, Thermoplastic	W	50 mm ² Ropelay	9.13mm	T6

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná

instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Naše portfolio silných značek:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE