


Joint Bond T8 Complete Welder Pair, Power

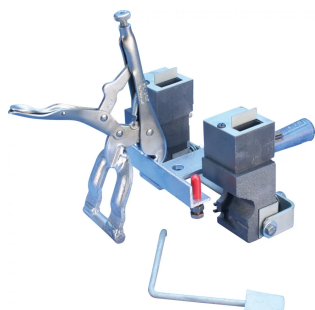

VLASTNOSTI

Complete welder assembly provides a convenient means of attaching jumper bonds to the head of the rail

Connection is made within the confines of the splice plate

Includes mold cleaner and flint ignitor

SPECIFIKACE

Rail Type: 85 lb to 141 lb T-Rail Sections

Bond Terminal Style: C

Table 1/1

Katalogové číslo	Article Number	Materiál	Conductor Size	Conductor Outer Diameter, Nominal	Bond Length	Welder Style
PBCT8X3		Graphite, Steel, Thermoplastic	50 mm ² Ropelay	9.13mm	177.8mm	T8
PBCT8X6	224422	Graphite, Steel, Thermoplastic	120 mm ² Ropelay	9.53mm	177.8mm	T8
PBCT82S13		Graphite, Steel, Thermoplastic	2/0 Concentric	10.62mm	330.2mm	T8
PBCT82J13		Graphite, Steel, Thermoplastic	2/0 Ropelay	12.19mm	330.2mm	T8
PBCT82J9		Graphite, Steel, Thermoplastic	2/0 Ropelay	12.19mm	228.6mm	T8

Katalogové číslo	Article Number	Materiál	Conductor Size	Conductor OuterDiameter, Nominal	Bond Length	Welder Style
PBCT8S6A13		Graphite, Steel, Thermoplastic	3/0 Composite	14.53mm	330.2mm	T8
PBCT82S9		Graphite, Steel, Thermoplastic	4/0 Ropelay	15.49mm	228.6mm	T8
PBCT8Y5X5		Graphite, Steel, Thermoplastic	95 mm ² Ropelay	15.52mm	177.8mm	T8
PBCT82W13		Graphite, Steel, Thermoplastic	250 kcmil Ropelay	19.05mm	330.2mm	T8

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE