

Mesh Bonding Network Connector, MBNC82



CERTIFICATIONS



VLASTNOSTI

Allows for fast, simple and economical field connection of grounding and bonding wires

Heavy duty clamps with stainless steel hardware are suitable for direct burial


Can accommodate additional pigtails that can be used to connect to building steel and equipment

Can be combined with Universal Pedestal Clamp for bonding to various pedestal sizes for mesh bonding networks

SPECIFIKACE

Table 1/1

Katalogové číslo	Materiál	Conductor Size
MBNC82	Bronze, Stainless Steel 304 (EN 1.4301)	#8 Solid - #2 Stranded, 10 mm ² Solid - 35 mm ² Stranded

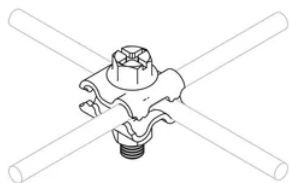

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE