

nVent ERICO Railclips, Hammer-On, Conductor Parallel



VLASTNOSTI

"Hammer-on" design

Securely holds conductors, reducing maintenance and improving wayside safety

Quick and easy hammer-on installation

Fits various rail profiles

Does not require removal of the ballast material



Multi-layer proprietary coating provides optimal corrosion protection

SPECIFIKACE

Rail Type:	85 lb to 141 lb T-Rail Sections
Povrchová úprava:	Multi-Layer Proprietary Coating
Materiál:	Spring Steel

Table 1/1

Katalogové číslo	Length (L)	Width (W)	Rail Foot Thickness (RFT)	Diameter (Ø)
SBA252S1	42.67mm	50.8 mm	13.21 mm	23.4 mm
SBA252S0	42.67mm	50.8 mm	13.21 mm	18.03 mm
SBA252S2	42.67mm	50.8 mm	13.21 mm	29.5 mm

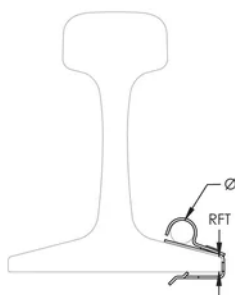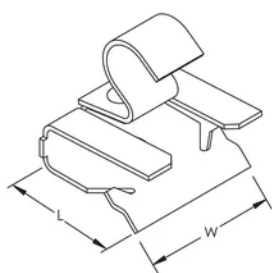

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRachte