

Rail Base Temporary Bond Connector



VLASTNOSTI

Can be used on most common rail types

Makes temporary signal bonds and track circuit connections using customer-supplied cable

Hardened contact points on clamps bite through rust and scale

Single conductor connection; solid or stranded

Unique design assures positive contact and firm grip


SPECIFIKACE

Table 1/2

Katalogové číslo	Materiál	Length (L)	Width (W)	Height (H)	Rail Foot Thickness (RFT)	Diameter (Ø)
A140	Ocel, Copper	63.5mm	25.4 mm	47.63 mm	15.24 mm Max	4.0 - 9.5 mm

Table 2/2

Katalogové číslo	Conductor Size
A140	#6 Solid - 1/0 Stranded, 10 mm ² Solid - 50 mm ² Stranded

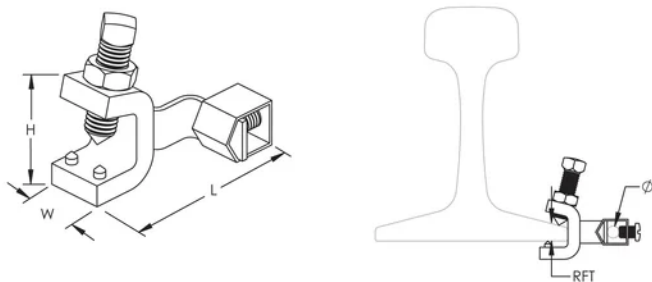

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Naše portfolio silných značek:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE